

## Han 24ES Press - F

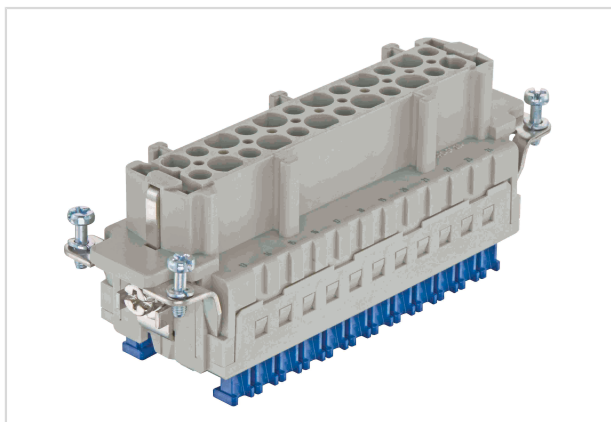


Image is for illustration purposes only. Please refer to product description.

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| Part number        | 09 33 024 2748                                                                        |
| Specification      | Han 24ES Press - F                                                                    |
| HARTING eCatalogue | <a href="https://b2b.harting.com/09330242748">https://b2b.harting.com/09330242748</a> |

### Identification

|          |                           |
|----------|---------------------------|
| Category | Inserts                   |
| Series   | Han <sup>®</sup> ES Press |

### Version

|                    |                                                         |
|--------------------|---------------------------------------------------------|
| Termination method | Cage-clamp termination                                  |
| Gender             | Female                                                  |
| Size               | 24 B                                                    |
| Number of contacts | 24                                                      |
| PE contact         | Yes                                                     |
| Details            | Blue slide<br>for hoods/housings high construction only |

### Technical characteristics

|                           |                              |
|---------------------------|------------------------------|
| Conductor cross-section   | 0.14 ... 2.5 mm <sup>2</sup> |
| Conductor cross-section   | AWG 26 ... AWG 14            |
| Rated current             | 16 A                         |
| Rated voltage             | 500 V                        |
| Rated impulse voltage     | 6 kV                         |
| Pollution degree          | 3                            |
| Rated voltage acc. to UL  | 600 V                        |
| Rated voltage acc. to CSA | 600 V                        |
| Insulation resistance     | >10 <sup>10</sup> Ω          |
| Contact resistance        | ≤3 mΩ                        |



Pushing Performance

## Technical characteristics

|                      |                 |
|----------------------|-----------------|
| Stripping length     | 9 ... 11 mm     |
| Limiting temperature | -40 ... +125 °C |
| Mating cycles        | ≥500            |

## Material properties

|                                           |                                                        |
|-------------------------------------------|--------------------------------------------------------|
| Material (insert)                         | Polycarbonate (PC)                                     |
| Colour (insert)                           | RAL 7032 (pebble grey)                                 |
| Material (contacts)                       | Copper alloy                                           |
| Surface (contacts)                        | Silver plated                                          |
| Material flammability class acc. to UL 94 | V-0                                                    |
| RoHS                                      | compliant with exemption                               |
| RoHS exemptions                           | 6(c): Copper alloy containing up to 4 % lead by weight |
| ELV status                                | compliant with exemption                               |
| China RoHS                                | 50                                                     |
| REACH Annex XVII substances               | No                                                     |
| REACH ANNEX XIV substances                | No                                                     |
| REACH SVHC substances                     | Yes                                                    |
| REACH SVHC substances                     | Lead                                                   |
| ECHA SCIP number                          | 5dbb3851-b94e-4e88-97a1-571845975242                   |

## Specifications and approvals

|                |                                                            |
|----------------|------------------------------------------------------------|
| Specifications | EN 60664-1<br>IEC 61984                                    |
| Approvals      | DNV GL                                                     |
| UL / CSA       | UL 1977 ECBT2.E235076<br>CSA-C22.2 No. 182.3 ECBT8.E235076 |

## Commercial data

|                                |                                                   |
|--------------------------------|---------------------------------------------------|
| Packaging size                 | 1                                                 |
| Net weight                     | 173 g                                             |
| Country of origin              | Germany                                           |
| European customs tariff number | 85389099                                          |
| eCl@ss                         | 27440205 Contact insert for industrial connectors |