

PIEZO ELECTRIC ALARM WITH INTERNAL CIRCUITRY




ROHS COMPLIANT

PART NUMBER:
BRP4526P-12-C

SPECIFICATIONS:

RATED VOLTAGE:	12 VDC
OPERATING VOLTAGE:	1 ~ 13 VDC
MAX CURRENT:	35 mA
SOUND OUTPUT LEVEL:	105dB @ 30CM
TERMINAL TYPE:	2 PINS
RESONANT FREQUENCY:	2900 ± 500 Hz
OPERATING TEMPERATURE:	-20 TO +60 °C
TONE MODE:	CONTINUOUS
FRAME DIAMETER:	45.0 mm
FRAME DEPTH:	26.0 mm
MOUNTING DIMENSIONS:	See Diagram

DIMENSIONS:

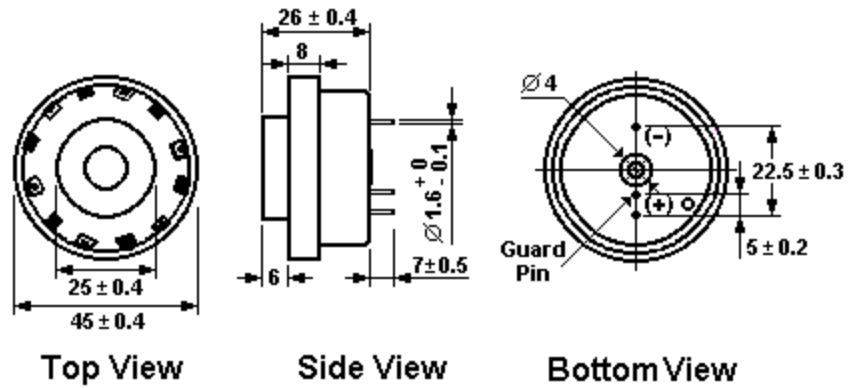

Top View

Side View

Bottom View

weight: 10 gms

FREQUENCY RESPONSE:

