



HOME • COMPANY PROFILE & PRODUCT OVERVIEW • PART SEARCH • CATALOG •

[Previous Page](#)

Product: **PIEZO ELECTRIC ALARM WITH INTERNAL CIRCUITRY**


Description: **ROHS COMPLIANT**

Part Number: **BRP4535S-24-C**

SPECIFICATIONS:

RATED VOLTAGE:	24 VDC
OPERATING VOLTAGE:	1 ~ 28 VDC
MAX CURRENT:	15 mA
SOUND OUTPUT LEVEL:	90dB @ 30CM
TERMINAL TYPE:	2 SCREW LUGS
RESONANT FREQUENCY:	2900 ± 500 Hz
OPERATING TEMPERATURE:	-20 TO +60 °C
TONE MODE:	CONTINUOUS
FRAME DIAMETER:	43.5 mm
FRAME DEPTH:	34.5 mm
MOUNTING DIMENSIONS:	Panel Mount

DIMENSIONS:

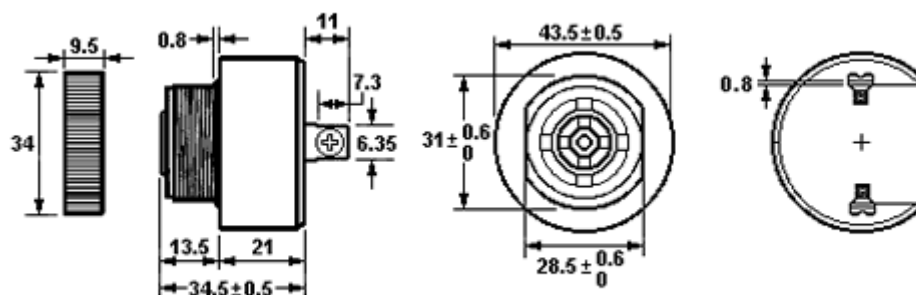

International Components Corporation

[Privacy Policy](#) | [Contact Us](#) | [SiteMap](#)

215 McCormick Dr. Bohemia New York, 11716 . Tel: 800-645-9154 . E-mail: info@icc107.com .ww