



[Previous Page](#)

[Printer Friendly Version](#)

Product: **PIEZO ELECTRIC ALARM WITH INTERNAL CIRCUITRY**

Description: **ROHS COMPLIANT**


Part Number: **BRP4535S-24-CD**



#### SPECIFICATIONS:

RATED VOLTAGE:	24 VDC
OPERATING VOLTAGE:	4 ~ 28
MAX CURRENT:	30/20 mA
SOUND OUTPUT LEVEL:	85/80dB @30CM
TERMINAL TYPE:	3 SCREW LUGS
RESONANT FREQUENCY:	2900 ± 500 Hz
OPERATING TEMPERATURE:	-20 TO +60 °C
TONE MODE:	CONT / INTERMIT
FRAME DIAMETER:	43.5 mm
FRAME DEPTH:	34.5 mm
MOUNTING DIMENSIONS:	Panel Mount

#### DIMENSIONS:

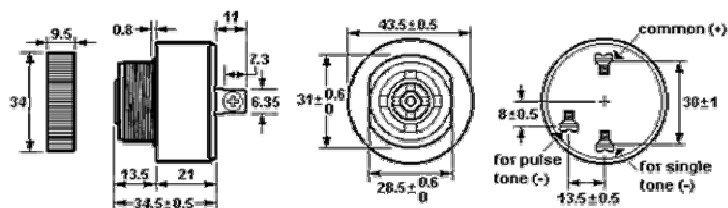

International Components Corporation

[Privacy Policy](#) | [Contact Us](#) | [SiteMap](#)

215 McCormick Dr. Bohemia New York, 11716 . Tel: 800-645-9154 . E-mail: info@icc107.com .www.icc107.com