




ELECTRO-ACOUSTIC TRANSDUCER

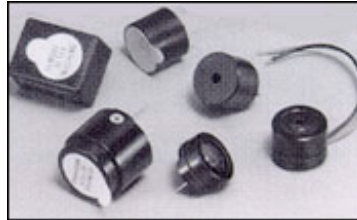

ROHS COMPLIANT AVAILABLE UPON REQUEST

PART NUMBER: **BRT1209P-01-50**

SPECIFICATIONS:

RATED VOLTAGE:	1.5 VDC
OPERATING VOLTAGE:	1 ~ 2
MAX CURRENT:	10 mA
SOUND OUTPUT LEVEL:	80dB @ 10 cm
TERMINAL TYPE:	2 PINS
RESONANT FREQUENCY:	2048 Hz
OPERATING TEMPERATURE:	-20 TO +60°C
TONE MODE:	CONTINUOUS
PULSE RATE:	N/A
COIL RESISTANCE:	50 ± 7.5
COIL IMPEDANCE:	140
FRAME DIAMETER:	12.0 mm
FRAME DEPTH:	8.5 mm
MOUNTING DIMENSIONS:	6.5 mm

COMMENTS:

*VALUE APPLYING RATED VOLTAGE (RESONANT FREQUENCY,

**VALUE APPLYING (RESONANT FREQUENCY, SINE WAVE, M

DIMENSIONS:

