




Part Number: 127007-0128
Converted to: XLR-2A-11C

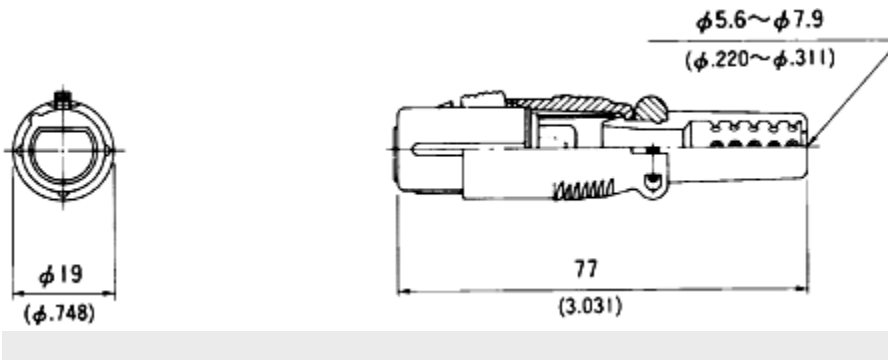

Product Family	Audio
Product Group	Audio XLR
Product Description	Most reliable commercial audio connector. Rigid metal shell with rubber insulator.
Product Series	Plug
Contact Arrangement	2A
Gender	Female
Shell Color	Silver
Contact Plating	Copper Alloy
Current Rating	15 A
Service Voltage (AC)	200 V
Dielectric Withstanding Voltage (AC)	1600 V

Contact Resistance	5 milliohms max.
Insulation Resistance	5,000 megaohms min. at 500 V DC
Temperature Rating	-55°C to + 125°C (-67°F to 257°F)
Wire Accommodation Reference AWG	#14
Wire Cross Section (max.)	2.0 mm ²
Stranded Wire O.D. (max.)	2.1 mm
Contact Material	Copper Alloy
Socket Insulator Material	Chloroprene
Pin Insulator Material	Nylon
Shell Material	Aluminum Alloy (Satin Nickel)
Barrel Material	Steel
Bushing Material	Chloroprene