

## PRODUCT DATASHEET OT CABLE CLAMP A-STYLE

OPTOTRONIC® Cable Clamp | Driver accessories



---

### Areas of application

- Downlights, flat luminaires
- Suitable for different cable types
- Suitable for indoor installations

---

### Product benefits

- Simple and quick cable mounting
- Sufficient space for cable connection
- Cost-effective and space-saving solution (TL version)
- Free cable connection thanks to open flaps
- Immediate installation thanks to pre-assembled cable clamps


---

### Product features

- Easy to install and flexible cable clamps
- Separate cable clamps for primary and secondary side
- Pre-fixed, captive screws
- Through-looping (TL version)

## TECHNICAL DATA

### Dimensions & Weight

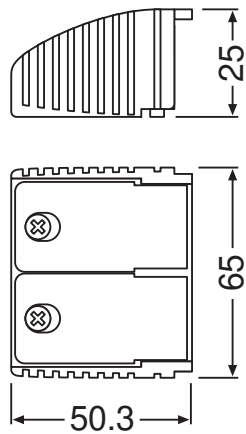

Length	35.0 mm
Width	65 mm
Height	25.0 mm
Product weight	29.00 g

### Temperatures & operating conditions

Max.housing temperature in case of fault	110 °C
Permitted rel. humidity during operation	5...85 % <sup>1)</sup>

<sup>1)</sup> Maximum 56 days/year at 85 %



### Certificates & Standards

Type of protection	IP20
--------------------	------

### LOGISTICAL DATA

Temperature range at storage	-40...+85 °C
------------------------------	--------------

### DOWNLOAD DATA

CAD/BIM files	Document name
 CAD STEP 3D	CC_A-Style
 CAD data 3D PDF	CAD data PDF OT Cable Clamp A-Style

## LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4052899089570	Unpacked 1		29.00 g	
4052899089587	Shipping box 20	336 mm x 110 mm x 68 mm	672.00 g	2.51 dm <sup>3</sup>

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

## DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.