

SERIES 1276 - SINGLE-POLE POWER TOOL SWITCHES




TO 8 (8) A 250 V AC

PRODUCT FEATURES







- ◆ Single-pole normally open contact (optionally with catch and switch-on lock)
- ◆ Powerful up to 13 A 125 V AC and 100 000 mechanical switching cycles
- ◆ M3 screw terminals and terminal connections for tinned wires and wire end ferrules

ON REQUEST

- ◆ Other connection variants
- ◆ Other operating force


Mechanical life endurance	1E5
Operating force	> 11 N (product-dependent)
Material	actuator housing
	PA glass fiber-reinforced PA / PA glass fiber-reinforced
Approval marks	 /  / 
Suitable for appliances of protection class II	




single-pole	Actuator color / printing	Housing color	8 (8) A 250 V AC 5E4	13 A 125 V AC	6 A 250 V AC	Connection type	Connection description	Contact material	Miscellaneous	Stock version
Normally open contact (SPNO)										
1276.0101			●	●	●		2 x M3 4 x terminal connection	Ag	lock	
1276.0601			●	●	●		2 x M3 4 x terminal connection	Ag	without lock special pushbutton for stronger spring (> 11 N)	



Basic type 1276

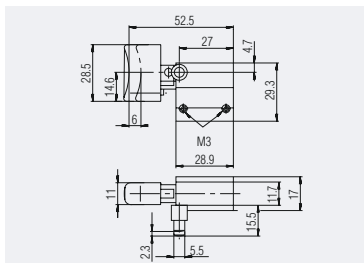

Socket terminal M3 mains side, terminal connection motor side 1276.0101

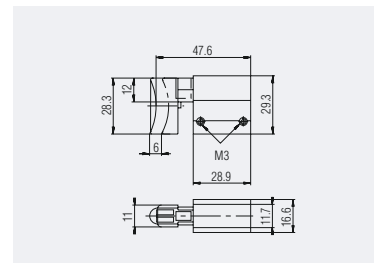

Socket terminal M3 mains side, terminal connection motor side 1276.0601

ROCKER SWITCHES

PUSHBUTTON SWITCHES

TOGGLE SWITCHES

SLIDE SWITCHES

ROTARY SWITCHES

FOOT SWITCHES

POWER TOOL SWITCHES

TACT AND KEY SWITCHES

SNAP-ACTION SWITCHES

MICRO SIGNAL SWITCHES

SENSORS