


# SERIES 1298 - SINGLE-POLE POWER TOOL SWITCHES

TO 8 (8) A 250 V AC

 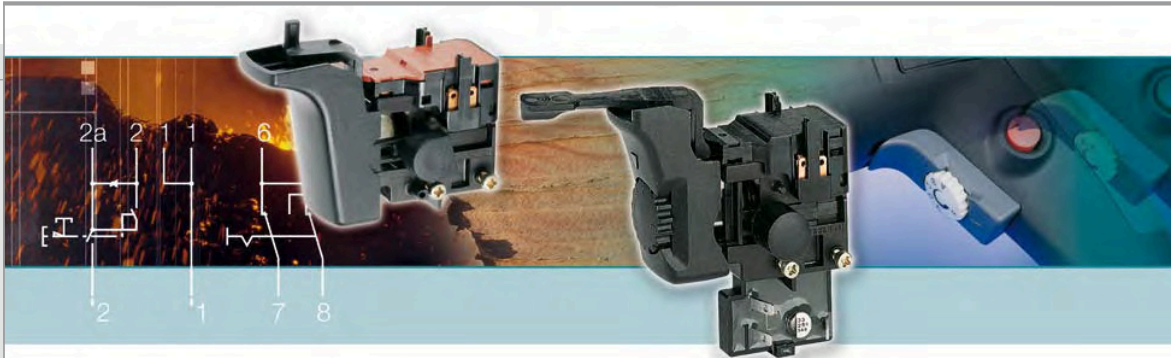


## PRODUCT FEATURES

- ◆ Single-pole normally open contact with bridging contacts in different electronic variants, e.g. half wave adjuster, half wave regulator, full wave adjuster, diode and linear potentiometer
- ◆ Alternatively as a double-pole changeover switch for currentless change in the direction of rotation, adjusting wheel for pushbutton travel

## ON REQUEST

- ◆ Other colors
- ◆ Other connection variants
- ◆ Higher rating up to 10 A 125 V AC and 100 000 switching cycles

Mechanical life endurance	10E4
Material	actuator housing
	PA / PA glass fiber-reinforced PA glass fiber-reinforced
Approval marks	
Suitable for appliances of protection class II	



ROCKER SWITCHES

PUSHBUTTON SWITCHES

TOGGLE SWITCHES

SLIDE SWITCHES

ROTARY SWITCHES

FOOT SWITCHES

**POWER TOOL SWITCHES**

TACT AND KEY SWITCHES



 

 



 

 

 


SNAP-ACTION SWITCHES

MICRO-SIGNAL SWITCHES

SENSORS


# SERIES 1298 - SINGLE-POLE POWER TOOL SWITCHES

TO 8 (8) A 250 V AC


 single-pole	Actuator color / printing	8 (8) A 250 V AC 5E4	Connection type	Connection description	Contact distance in mm	Contact material	Setting wheel angle	Miscellaneous	Stock version
<b>Normally open contact (SPNO)</b>									
<b>1298.0101</b>		●		2 x M3 4 x terminal connection	≈ 3	Ag		with lock	
<b>1298.0301</b>		●		2 x M3 4 x terminal connection	≈ 3	Ag		small actuator small locking actuator	
<b>1298.2201</b>		●		2 x M3 4 x terminal connection	≈ 3	Ag	296.5°	lock adjusting wheel	
<b>1298.5201</b>		●		2 x M3 4 x terminal connection 4 x 2.8 x 0.8	≈ 3	Ag		lock R-L switch	
<b>1298.5401</b>		●		2 x M3 4 x terminal connection 4 x 2.8 x 0.8	≈ 3	Ag		lock width design R-L switch	
<b>1298.7101</b>		●		2 x M3 4 x terminal connection 4 x 2.8 x 0.8	≈ 3	Ag	296.5°	lock R-L switch adjusting wheel	
<b>1298.7312</b>		●		2 x M3 4 x terminal connection 4 x 2.8 x 0.8	≈ 3	Ag	296.5°	small locking pushbutton small pushbutton R-L switch, adjusting wheel	




Basic type 1298

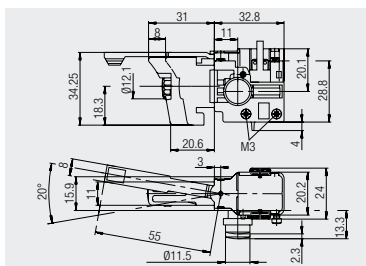


Socket terminal M3 mains side, screwless push-in terminal motor side, quick-connect terminal, 1298.7101

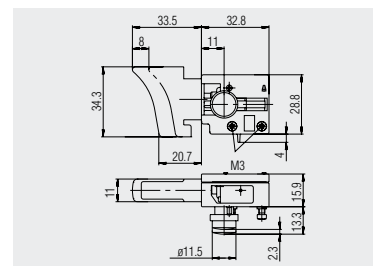

Socket terminal mains side, screwless push-in terminal motor side 1298.0101

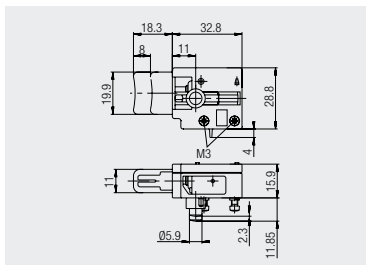

Socket terminal M3 mains side, screwless push-in terminal motor side 1298.0301

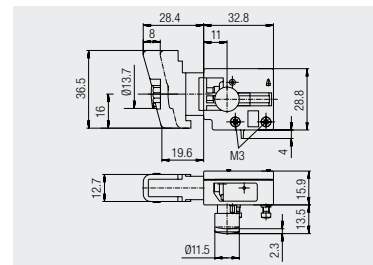

Socket terminal M3 mains side, screwless push-in terminal motor side 1298.2201

ROCKER SWITCHES

PUSHBUTTON SWITCHES

TOGGLE SWITCHES

SLIDE SWITCHES

ROTARY SWITCHES

FOOT SWITCHES

**POWER TOOL SWITCHES**

TACT AND KEY SWITCHES

SNAP-ACTION SWITCHES

MICRO-SIGNAL SWITCHES

SENSORS