

SERIES 1299 - SINGLE-POLE POWER TOOL SWITCHES

TO 6 (6) A 250 V AC

PRODUCT FEATURES

- ◆ Single-pole normally open contact with integrated potential-free linear potentiometer
- ◆ Powerful with up to 6 A at 100 000 mechanical switching cycles
- ◆ With lock

ON REQUEST

- ◆ Other colors
- ◆ Other actuator forms
- ◆ Other connection variants
- ◆ As changeover switch
- ◆ Right / left rotation
- ◆ Without lock
- ◆ Higher rating


Mechanical life endurance	1E5
Contact distance	> 3 mm
Material	actuator housing connections
	PA / PA glass fiber-reinforced PA glass fiber-reinforced chromated
Approval marks	
Suitable for appliances of protection class II	



single-pole	Actuator color / printing	6 (6) A 250 V AC 5E4	13 A 125 V AC	Connection type	Connection description	Contact material	Miscellaneous	Stock version
Normally open contact (SPNO)								
1299.0101		●	●		2 x M3 4 x terminal connection	Ag	R = 220 kOhm	



Basic type 1299

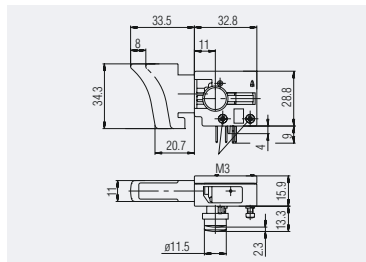

Socket terminal M3, terminal connection

ROCKER SWITCHES

PUSHBUTTON SWITCHES

TOGGLE SWITCHES

SLIDE SWITCHES

ROTARY SWITCHES

FOOT SWITCHES

POWER TOOL SWITCHES

TACT AND KEY SWITCHES

SNAP-ACTION SWITCHES

MICRO-SIGNAL SWITCHES

SENSORS