


Part Number: TZ03P450F169B00

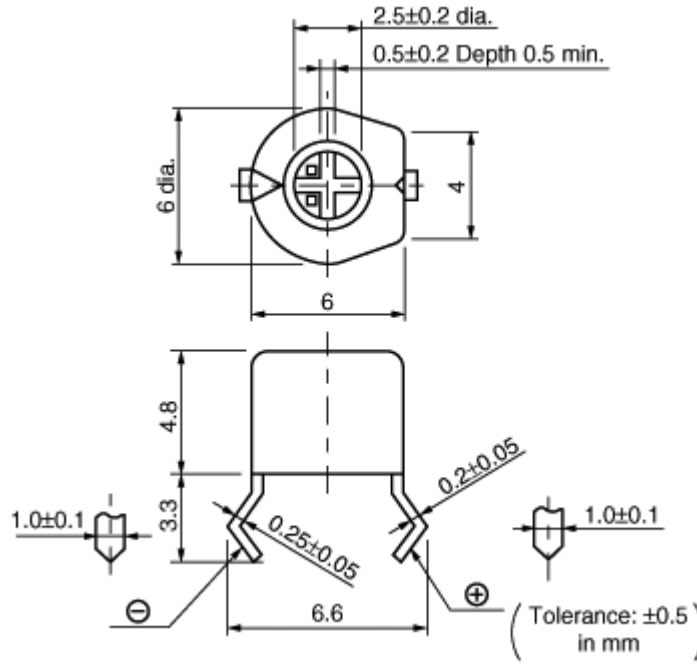

Features

- 1. Color coded case facilitates identification of capacitance range.
- 2. Sealed construction prevents the penetration of flux and dust.
- 3. Available in two adjustment styles: Top/Rear.
- 4. + (Cross-shaped) slot enables automatic adjustment.

Applications

- 1. Car audio systems
- 2. Car clocks
- 3. Stereos
- 4. Radio cassette tape recorders
- 5. Cordless telephones
- 6. Video games
- 7. Compact radio equipment
- 8. Remote keyless entry systems
- 9. Burglarproof devices

Specification

Global Part Number	TZ03P450F169B00
Previous Part Number	TZ03P450FR169
Cmin. (max.)	6.8pF
Cmax.	45.0pF +50/-0%
TC	N1200±500ppm/°C
Q	300min. at 1MHz, Cmax.
Rated Voltage	100Vdc
Withstanding Voltage	220Vdc
Insulation Resistance (min.)	10000M ohm
Torque	2.0 to 14.7mNm
Operating Temperature Range	-25 to +85°C
Stator/Case Color	Yellow
Adjustment Direction	Top
Soldering Method	Flow
Height	4.8mm ±0.5
Weight	0.4g