

Magnecraft

191 Waukegan Rd, Ste 206

Northfield, IL 60093-2743

Phone: (847)441-2526

Fax: (847)441-2522



Email: info@magnecraft.com

Item # 70-178-2, 70-178-2 Socket / 15 Amp Rating, 300 Volts

70-178-2 Socket / 15 Amp Rating, 300 Volts

11 Pin, Printed Circuit Terminals without Mounting Tabs

This Item is Normally Stocked

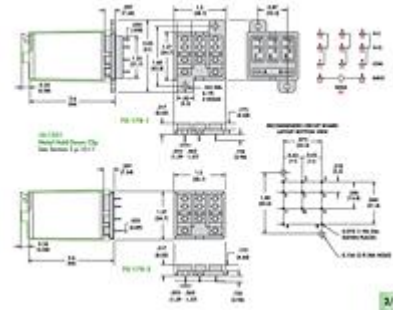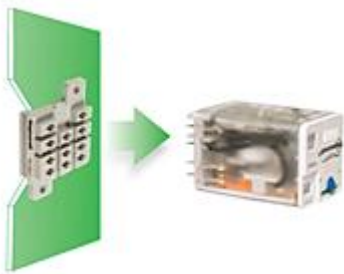

[SPECIFICATIONS](#) · [ELECTRICAL RATING](#) · [DIELECTRIC STRENGTH](#) · [TEMPERATURE](#) · [CONSTRUCTION](#) · [MISCELLANEOUS](#)

SPECIFICATIONS

Contact Configuration	Triple Pole
Mounting Style	PC Adaptor
Rated Current	15 - 16 A
Number of Terminals	11

ELECTRICAL RATING

Nominal Voltage Rating	300 V
Nominal Current Rating	15 A

DIELECTRIC STRENGTH

Output to Adjacent Output Terminals	2500 V (rms)
Output to Input Terminals	2500 V (rms)

TEMPERATURE

Operating Range	- 40 to + 80 °C
Storage Range	- 40 to + 105 °C

CONSTRUCTION

Internal Metal Tracks	Copper Alloy Zinc Plated
Terminals	Copper Alloy Zinc Plated

MISCELLANEOUS

Socket Mounting	Chassis
Wire Size Capacity (Maximum), EN 60204-1, Solid Cu	(Output): 16 AWG, 1.0 mm ²
Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu	(Output): 16 AWG, 1.0 mm ²
Wire Connection Method	Solder
Flammability Rating	94V-0 Class
Body Color	Light Gray
Product Certification	CSA UL
Conformance	CE RoHS