


# SLIDE SWITCHES

PRODUCT NUMBER 4021.0101



## TECHNICAL DATA

<b>Product number</b>	<b>4021.0101</b>	
Actuator color / printing		
Product family	Slide switches	
Actuation type	direct	
Weight	5.000 g	
ROHS conform	yes	
Switching function	Changeover switch (DPDT)	
Material fixed contact	Cu silver-plated	
Number of poles	2 - pole	
connections	Solder terminal	
Mechanical life endurance	1E4	
Rating IEC	2 (0.5) A 250 V AC	
Contact resistance (new condition)	< 100 (1 A 12 V DC) mOhm	
Insulation resistance (new condition)	> 100 (500 V DC) MOhm	
Voltage strength at 250 V	→ function insulation / basic insulation	1 500 V
	→ reinforced insulation	3 000 V
	→ small contact distance	500 V
Proof tracking	250 PTI	
Insulation spacing	acc. to EN 61058 for reinforced or double insulation	
Protection type	→ Connection	IP 40
	→ Actuator	IP 40
Ambient temperature	→ connection side	-20 °C ... +80 °C
Ambient temperature	→ Actuation side min.	-20 °C
Storage temperature	-40 °C ... +80 °C	
Flammability	UL 94 V-2	
Glow wire test temperature	850 °C	
Actuators and additional actuators	slide: PA, red	


Housing description	housing: PA, black base plate: hard paper
Connection surface	→ bearing connection silver plated → external connection silver plated
Contact material	CuSn silver plated
Contact distance	≥ 3 mm
Contact type	slide contact
Plug force of the terminals	≤ 60 N
Additional labeling	site, year, week of manuf. acc. to DIN EN 60062
Type of fastening	screw fastening
Degree of pollution	3
Stock version	●

## PRODUCT IMAGE



(Similar to original product)

## DRAWINGS

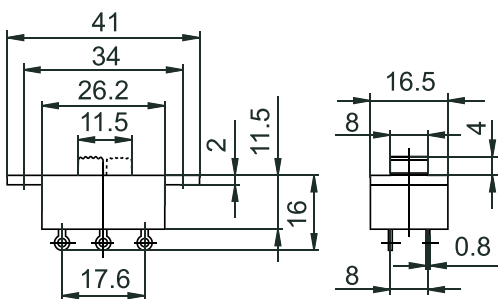

Technical changes reserved. Dimensions are not binding.

Detailed specifications available on request.

Marquardt GmbH · Schloss-Straße 16 · 78604 Rietheim-Weilheim · Germany  
Phone: +49 (0) 7424 / 99-0 · Fax: +49 (0) 7424 / 99-2399 · [www.marquardt.com](http://www.marquardt.com) · [marquardt@marquardt.de](mailto:marquardt@marquardt.de)