


# FAN CORDS


- Comply with UL, and CSA requirements
- Ratings: UL Rated 10 AMP/125 VA CSA Rated 7 AMP/125 VAC
- Constructed from 2 conductor 18 AWG SPT-1 105 C VW-1
- Straight and 90 degree style plugs available
- 2 prong style plugs available in all lengths

## Straight Style

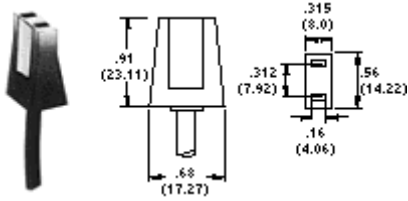

Cord Sets	Length	Model No.
Straight Style	24"	432000
	36"	432020
	48"	432002

## 90 Degrees Style

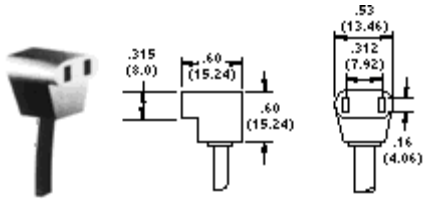

Cord Sets	Length	Model No.
90 degree	36"	432021

## 2 Prong Style



Cord Sets	Length	Model No.
2 Prong Style	24"	432050
	36"	432051
	48"	432052