


D-Subminiature Hoods

All Hood Kits Include: Hardware and Strain Relief.

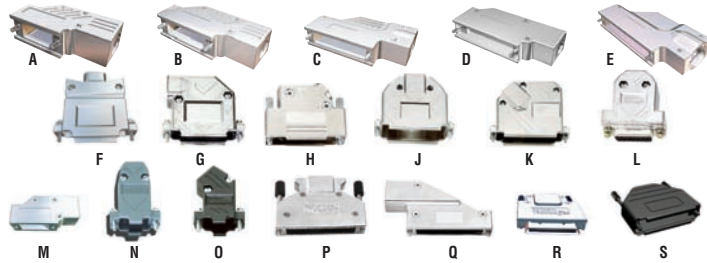

Ultra-Low Profile 90° Metal Backshells (Nickel Plated)

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0075	N30E900000	9	A	90° Exit ULP with Grommets	4.35	3.94	3.60
810-0097	N30E910000	15	B	90° Exit ULP with Grommets	4.61	4.20	3.85
810-0098	N30E920000	25	C	90° Exit ULP with Grommets	5.92	5.39	4.93
810-0200	N30E950000	25	D	90° Exit ULP Staple Strain Relief	5.11	4.64	4.26
810-0099	N30E930000L	37	E	90° Exit ULP with Grommets	6.94	6.31	5.78
810-0209	N30E940000L	50	E	90° Exit ULP with Grommets	7.67	6.97	6.38

EMI/RFI Shielded Metal Backshells (Zinc Plated)

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0012	C88E000218	9	F	Straight Exit	2.91	2.65	2.42
810-0039	C88E000207	15	F	Straight Exit	3.15	2.86	2.62
810-0033	C88E000203	25	F	Straight Exit	3.22	2.92	2.67
810-0060	C88E000206	37	F	Straight Exit	4.38	3.98	3.64
810-0058	C88E000208	50	F	Straight Exit	4.27	3.89	3.56
810-0030	C88E420000	25	G	90° Exit	3.43	3.11	2.85

EMI/RFI Shielded Metal Backshells (Nickel Plated)

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0054	MHDE45ZK9K	9	H	45° Exit with Thumbscrews	3.85	3.48	3.19
810-0039	MHDE45ZK15K	15	H	45° Exit with Thumbscrews	3.94	3.56	3.26
810-0027	MHDE45ZK25K	25	H	45° Exit with Thumbscrews	5.06	4.51	4.10
810-0079	MHDE45ZK37K	37	H	45° Exit with Thumbscrews	5.24	4.72	4.29

EMI/RFI Shielded Metal Backshells Straight Cable Exit (Nickel Plated)

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0193	MHDETZ9K	9	—	Straight Exit with Thumbscrews	3.85	3.50	3.18
810-0222	MHDETZK15K	15	—	Straight Exit with Thumbscrews	3.75	3.41	3.12
810-0223	MHDETZK25K	25	—	Straight Exit with Thumbscrews	4.30	3.92	3.59
810-0224	MHDETZK37K	37	—	Straight Exit with Thumbscrews	4.72	4.29	3.93

Metallized Plastic Backshells

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0034	C88E301000	9	J	Straight	1.63	1.47	1.35
810-0010	C88E311000	15	J	Straight	1.82	1.65	1.51
810-0021	C88E321000	25	J	Straight	2.06	1.86	1.71
810-0100	C88E330000	37	J	Straight	3.30	2.99	2.74
810-0068	C88E340000	50	J	Straight	3.55	3.22	2.95
810-0022	C88E201000	9	K	45°	1.69	1.52	1.40
810-0011	C88E211000	15	K	45°	1.78	1.60	1.47
810-0023	C88E221000	25	K	45°	2.13	1.92	1.76
810-0101	C88E231000	37	K	45°	3.41	3.10	2.84

Die Cast Metal Ethernet Backshells

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0078	C88E610000	15	L	Straight/Short	3.81	3.46	3.15
810-0089	C88E610001	15	L	Straight/Long	3.85	3.50	3.18
810-0102	C88E610002	15	L	90° Exit	3.84	3.50	3.20
810-0064	C88E600000	9	M	90° Exit Ultra Low Profile	2.68	2.45	2.23

Non-Shielded Plastic 2-Piece Backshells

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0157	C88E301005	9	N	Straight/Gray	1.14	1.02	.93
810-0158	C88E301004	9	N	Straight/Black	1.28	1.15	1.05
810-0159	C88E311005	15	N	Straight/Gray	1.28	1.14	1.04
810-0160	C88E311004	15	N	Straight/Black	1.28	1.14	1.04
810-0156	C88E321005	25	N	Straight/Gray	1.34	1.20	1.10
810-0161	C88E321004	25	N	Straight/Black	1.34	1.20	1.10
810-0162	C88E331005	37	N	Straight/Gray	1.47	1.34	1.23
810-0163	C88E330004	37	N	Straight/Black	1.51	1.36	1.25
810-0164	C88E200005	9	O	45°/Gray	1.16	1.04	.95
810-0165	C88E201004	9	O	45°/Black	1.15	1.03	.94
810-0166	C88E210005	15	O	45°/Gray	1.26	1.14	1.03
810-0167	C88E210004	15	O	45°/Black	1.26	1.14	1.03
810-0168	C88E220005	25	O	45°/Gray	1.37	1.24	1.13
810-0169	C88E221004	25	O	45°/Black	1.39	1.25	1.14
810-0170	C88E230005	37	O	45°/Gray	1.48	1.35	1.24
810-0198	C88E230004	37	O	45°/Black	1.48	1.35	1.24

SCSI/VHDCI Backshells (EMI/RFI Shielded)

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0114	N90E110000	50	P	Straight with Thumbscrews	6.92	6.29	5.76
810-0115	N90E120000	68	P	Straight with Thumbscrews	7.09	6.45	5.90
810-0055	N94E120000	68	Q	90° with Jackscrews	7.38	6.71	6.15
810-0206	N90E620000	68†	R	Straight with Thumbscrews	5.41	4.90	4.48

†VHDCI.

Non-Shielded Plastic 1-Piece Backshells with Thumbscrews

Stock No.	Mfr.'s Type	No. of Pos.	Fig.	Description	EACH		
					1-49	50-99	100-249
810-0019	MHDEPPK9BLACK-K	9	S	Straight/Black	1.90	1.73	1.58
810-0020	MHDEPPK15BLACK-K	15	S	Straight/Black	1.90	1.73	1.58
810-0062	MHDEPPK25BLACK-K	25	S	Straight/Black	2.04	1.82	1.66
810-0083	MHDEPPK37BLACK-K	37	S	Straight/Black	2.12	1.91	1.75

D-Subminiature Crimp Connector/Cover Kits



Shielded Kits — Male

Stock No.	Mfr.'s Type	Kit Type	No. of Pos.	EACH		
				1-24	25-49	50-99
810-0171	C270E09500	Metal	9	3.79	3.43	3.13
810-0172	C270E15510	Metal	15	4.65	4.21	3.85
810-0173	C270E25520	Metal	25	5.94	5.38	4.93
810-0174	C270E09650	Metallized-Plastic	9	3.54	3.20	2.92
810-0175	C270E15660	Metallized-Plastic	15	4.43	4.02	3.68
810-0176	C270E25670	Metallized-Plastic	25	5.57	5.04	4.60

Shielded Kits — Female

Stock No.	Mfr.'s Type	Kit Type	No. of Pos.	EACH		
				1-24	25-49	50-99
810-0177	C271E09500	Metal	9	3.79	3.43	3.13
810-0178	C271E15510	Metal	15	4.65	4.21	3.85
810-0179	C271E25520	Metal	25	5.88	5.33	4.88
810-0180	C271E09650	Metallized-Plastic	9	3.54	3.20	2.92
810-0181	C271E15660	Metallized-Plastic	15	4.39	3.98	3.64
810-0182	C271E25670	Metallized-Plastic	25	5.57	5.04	4.60

Unshielded Kits — Male

Stock No.	Mfr.'s Type	Kit Type	No. of Pos.	EACH		
				1-24	25-49	50-99
810-0118	C270E09750	Black Plastic	9	3.17	2.88	2.64
810-0119	C270E15760	Black Plastic	15	4.04	3.67	3.34
810-0074	C270E25770	Black Plastic	25	4.76	4.32	3.96

Unshielded Kits — Female

Stock No.	Mfr.'s Type	Kit Type	No. of Pos.	EACH		
				1-24	25-49	50-99
810-0094	C271E09750	Black Plastic	9	3.17	2.88	2.64
810-0116	C271E15760	Black Plastic	15	3.89	3.53	3.23
810-0117	C271E25770	Black Plastic	25	4.96	4.48	4.10

Hardware and Accessories



Stock No.	Mfr.'s Type	Fig.	Description	EACH		
				1-49	50-99	100-249
810-0063	B71E014254	A	4-40 x 0.80" Thumbscrew	.22	.20	.18
810-0009	B71E014276	A	4-40 x 1.75" Thumbscrew	.28	.25	.22
810-0076	B71E014255	A	4-40 x 1.90" Thumbscrew	.28	.25	.22
810-0048	B71E014256	A	4-40 x 1.94" Thumbscrew	.28	.25	.22
810-0049	B71E300611M25	A	M2.5 x 1.94" Thumbscrew	.27	.25	.23
810-0050	B71E300612M26	A	M2.6 x 1.90" Thumbscrew	.27	.25	.22
810-0051	B71E300613M3	A	M3 x 1.90" Thumbscrew	.26	.24	.22
810-0126	B71E3005134M25S	B	M2.5 x 1/2" Captive Screw	.48	.43	.39
810-0088	B71E3005134M26S	B	M2.6 x 1/2" Captive Screw	.50	.44	.40
810-0127	B71E3005134M3S	B	M3 x 1/2" Captive Screw	.48	.43	.39
810-0029	C89E014009*	C	4-40 Female Screwlock Set/2	.58	.52	.47
810-0210	C89E014009M3*	C	M3 Female Screwlock Set/2	.60	.54	.49
810-0015	C89E014008*	D	Male Screwlock Set/2	.63	.54	.50
810-0067	C89E014050*	E	4-40 Hex Extender Set/2	.97	.87	.79
810-0207	C89E014051*	E	M2.5 Hex Extender Set/2	1.20	1.08	.98
810-0014	C89E014020	—	9 Position Slide Latch Kit	1.26	1.15	1.05
810-0103	C89E014021	—	15 Position Slide Latch Kit	1.82	1.62	1.46
810-6110	C89014006*†	—	Locking Posts ST/2	.86	.77	.69

*PER SET/2. †Not RoHS Compliant.

D-Subminiature Shielded Overmold Cans

One-piece design provides excellent EMI/RFI shielding and reduces assembly time. Accommodates standard crimp connectors from most manufacturers. Cable Dia. Range: 0.200" to 0.375" (9/15/25). Material: CR steel. Finish: Tin over copper.



Stock No.	Mfr.'s Type	No. of Pos.	Cable Exit Diameter	EACH		
				1-49	50-99	100-249
810-0106	A30E800900	9	0.372"	.53	.47	.42
810-0013	X9PEM2	9	0.283"	.58	.51	.47
810-0035	W9PEM3	9	0.200"	.69	.60	.54
810-0077						