

REV.	SPECIFICATION	ECN NO.	APPD.






Material:

Housing: Thermoplastic Polyester UL94V-0.
 Contact Pin: Copper Alloy, Tin Plated.
 Flange NUT: Copper Alloy, M2.5.

Electrical Characteristics:

Voltage Rating: 300V.
 Current Rating: 10A.
 Withstanding Voltage: 1.6KV.
 Operating Temperature: -40°C~+115°C.

***RoHS Compliant**

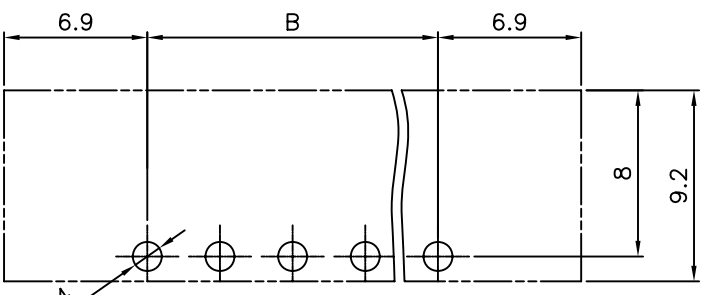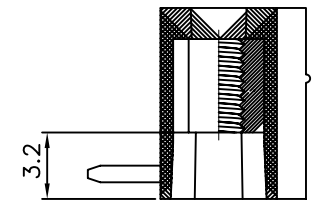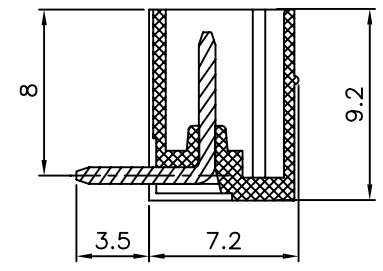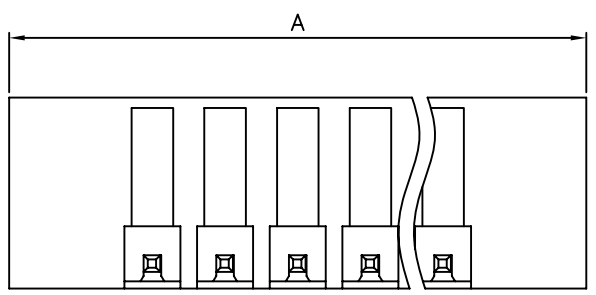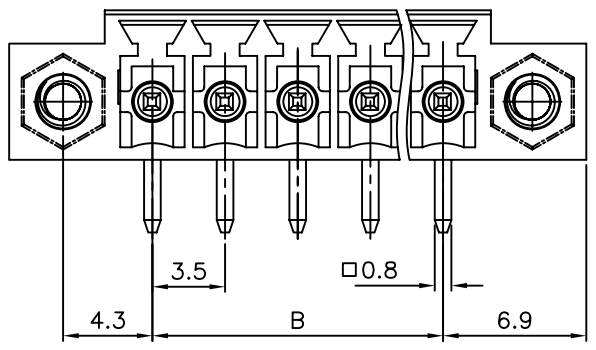

P.C.Board Layout

8930- Series C Pitch 3.5mm 072092 Manufacturing Code G:Green, B:Black, Y:Grey, U:Blue CA:With Flange xx No. of Positions R:Right Angle B: Bulk Package for 2~5Pos. Box Package for 6~24Pos.

Position Dimension	02 Thru 24
A	No. of Positions*3.5+10.3
B	(No. of Positions-1)*3.5

Tolerances	Dwg. No.	8930D01007	Title:		8930 Series 3.5mm Terminal Block (8300-xxMTR11-03)	 OUPIIN ELECTRONIC(KUNSHAN) CO., LTD. P/N: 8930-C072092GCAxxRB				
x = ±0.5	Projection		Scale							1:1
.x = ±0.30	Unit	mm	Scale	1:1						
.xx = ±0.15	Drawn By	PEGGY11/20'14	①780							
SHEET		1/1	Ver.No.	A4						