




AC Crossaxial Blower

OAB60 series

Impeller: Aluminum Alloy
 Motor: AC Shaded pole
 Insulation Class: E.B.F
 Insulation Withstand: AC 1500V/1 minute
 Insulation Resistance: >100M ohm DC500V
 Operating Temp: 0C ~ +45C



Bearing: *
 Indicate "B" for Ball bearing or "S" for Sleeve

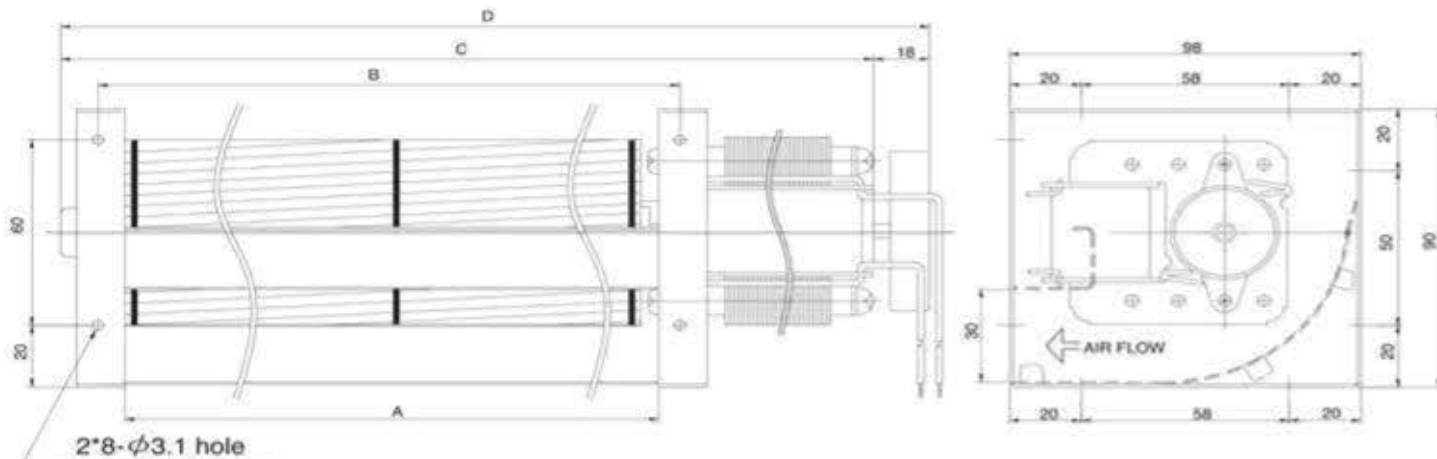

Spec. Model	Size (mm)				Rated Voltage V	Rated Frequency Hz	Rated Current A	Input Power W	Speed r.p.m.	Max Pressure mmHg	Maximum Air Flow m ³ /min	CFM	Noise dBA	Safety Approval		Weight g
	A	B	C	D										UL	CE	
OAB60184-11-2 *	184	199	257		120	60	0.33	23	1700	3.8	1.8	63	35		○	1200
OAB60184-22-2 *					230	50	0.17	23	2000	3.7	2.5	88	39		○	
OAB60184-11-1 *	184	199	262	280	120	60	0.55	37	2500	7.3	3.0	106	47	○	○	1350
OAB60184-22-1 *					230	50	0.27	34	2500	5.4	3.0	106	47	○	○	
OAB60245-11-2 *	245	260	323		120	60	0.42	31	1900	4.9	2.9	102	41		○	1400
OAB60245-22-2 *					230	50	0.23	31	2000	3.9	3.3	118	42		○	
OAB60245-11-1 *	245	260	323	341	120	60	0.60	42	2000	5.1	3.0	106	42	○	○	1500
OAB60245-22-1 *					230	50	0.27	35	2200	4.6	3.8	133	44	○	○	
OAB60306-11-1 *	306	321	384	402	120	60	0.63	42	1900	4.7	3.2	114	42	○	○	1500
OAB60306-22-1 *					230	50	0.28	36	2200	4.6	4.4	154	44	○	○	
OAB60368-11-1 *	368	383	446	464	120	60	0.64	43	1700	3.0	3.8	133	41	○	○	1600
OAB60368-22-1 *					230	50	0.30	38	2000	4.2	4.7	167	43	○	○	
OAB60429-11-1 *	429	444	507	525	120	60	0.64	44	1600	2.2	3.9	139	41	○	○	1650
OAB60429-22-1 *					230	50	0.31	40	1800	3.3	5.1	180	43	○	○	

