


Headers

Mass Terminated Connector System Male Headers Mate With Female Connectors

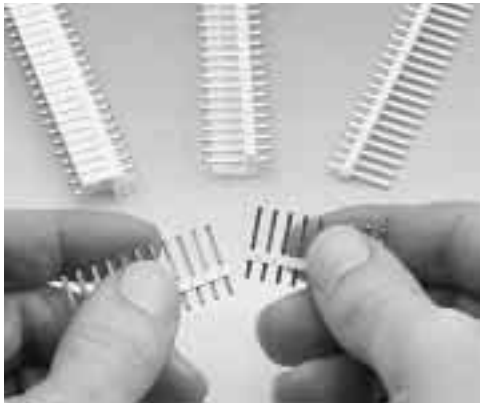

Headers/Part Numbers System:

*MAS-CON headers are breakable molded wafers, dimensionally more accurate than extruded, proven to be very cost effective for prototyping or small production runs.

Part Numbers System:

M = Male	→	M
F = Standard	→	F
L* = Locking		
P = Polarizing		
S = Straight Post	→	S
A = Angled Post		
S = Square Pin	→	S
100 = 0.100" spacing (2.54 mm)	→	100
156 = 0.156" spacing (3.96 mm)		
No. of circuits (See table below)	→	10
Packaging quantity (See table below)	→	D
Contact Plating	→	.
Blank = Tin Plating		
B = 15µmin Gold over Nickel		

Packaging Quantity

Spacing	No. of Circuits	Spacing	No. of Circuits	Standard Packs	
				Code	Qty Pcs.
0.100" (2.54 mm)	2 – 5	0.156" (3.96 mm)	2 – 5	D	500
	6 – 36		6 – 24	C	100

*For MLSS100 and MLAS100 - Circuits 2-12 and 14 positions are solid black wall and are not breakable.