


REV. 2  
DCO 102710

COIL: @ 25°C	
RESISTANCE	300 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	7.0 VDC MAX, 2.3 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES: OPERATE & RELEASE 15 MS MAX.	
OPERATE BOUNCE 5 MS MAX.	
RELEASE BOUNCE 5 MS MAX.	

CUSTOMER DATA SHEET

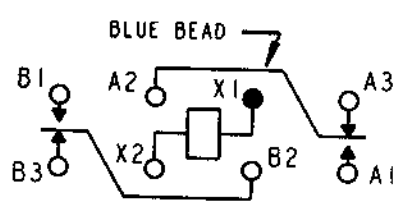

TERMINAL VIEW

CONTACT RATING:	10 AMPS 28 VDC
	5 AMPS 115 VAC/400 Hz RESISTIVE
	50,000 OPERATIONS

DR. BSH 8/17/01 CK. TLG 8-20-01



CUST.	OPL
CUST. NO.	M5757/23-005 REV.

"07" RELAY

B07D034BC2-0053