


REV. 2

DCO 141865

COIL: @ 25°C	
RESISTANCE	1350 OHMS ± 10%
NOMINAL VOLTAGE	20.0-35.0 VDC (26.5)
MUST OPERATE	13.5 VDC
MUST RELEASE	8.1 VDC MAX, 1.5 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	100 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES: OPERATE & RELEASE 4 MS MAX.	
BOUNCE 1.5 MS MAX.	
DIELECTRIC 500 VAC - ALL POINTS	

CUSTOMER DATA SHEET

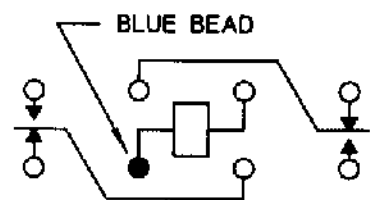

TERMINAL VIEW

CONTACT RATING:	2A 28VDC RES.,
	0.5A 28VDC IND. L/R .008 MAX., 0.5A
	115VAC CASE UNGROUNDED, .125A 115VAC
	CASE GROUNDED RES., 100,000 OPS

DR. R.B. 10/4/96 CK 3/7/00



CUST. C.I.I. STD.
CUST. NO. _____ REV. _____

'3SBC' RELAY

3SBC5004K1