




Product Number: 2-1445359-2

MTA-50 IDC Connectors and Headers

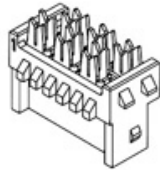

Product Type Features:

Product Type = Receptacle Assembly
Connector Type = Feed Thru
Number of Positions = 22
Wire Size (mm² [AWG]) = 0.12-0.15² [26]
Comment = Make to order

Electrical Characteristics:

Voltage Rating (VAC) = 30
Current Rating (Amps.) = 1
Resistance, Low-Level (mΩ) = 30

Body Related Features:

Centerline (mm [in]) = 1.27 [0.050]
Polarized = Yes
Cable Insulation Diameter (mm [in]) = 0.99 [0.039]
Flammability Rating = UL 94V-2

Contact Related Features:

Contact Mating Area Plating Material = Tin
Contact Material = Phosphor Bronze

Housing Related Features:

Housing Color = Blue
Housing Material = Thermoplastic

Industry Standards:

RoHS/ELV Compliance = RoHS compliant, ELV compliant
Lead Free Solder Processes = Not relevant for lead free process
RoHS/ELV Compliance History = Converted to comply with RoHS directive

Conditions for Usage:

Terminate To = Ribbon Cable
Operating Temperature (°C) = -55 - +105

Other:

Brand = AMP