


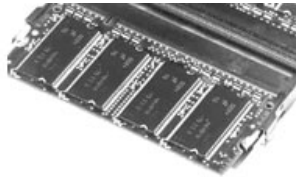

Product Number: 2-1734073-2

Memory Sockets



Product Type Features:

Product Type = SO DIMM

Number of Positions = 200

DRAM Type = Double Data Rate (DDR)

Module Orientation = Right Angle

Mechanical Attachment:

Keying = Standard

Electrical Characteristics:

DRAM Voltage = 1.8 V

Termination Related Features:

Solder Tail Contact Plating = Gold (2) over Nickel

Body Related Features:

Row-to-Row Spacing (mm [in]) = 6.20 [0.244]

Centerline (mm [in]) = 0.60 [0.024]

Number of Rows = Dual

Ejector Type = Locking

Ejector Location = Both Ends

Number of Keys = 1

Socket Type = Reverse

Latch Material = Stainless Steel

Boss = With

Contact Related Features:

Contact Mating Area Plating Material = Gold (2) over Nickel

Contact Mount = Surface Mount

Contact Material = Copper Alloy

Housing Related Features:

Housing Material = High Temperature Thermoplastic

Housing Color = Black

Housing Flammability Rating = UL 94V-0

Configuration Related Features:

Stack Height (mm [in]) = 9.20 [0.362]

Insertion Style = Cam-In

Center Key (mm [in]) = None

Industry Standards:

RoHS/ELV Compliance = RoHS compliant, ELV compliant

Lead Free Solder Processes = Reflow solder capable to 245°C, Reflow solder capable to 260°C

RoHS/ELV Compliance History = Always was RoHS compliant

Operation/Application:

Application Type = DDR SDRAM

Packaging Related Features:

Packaging Method = Tape & Reel

Packaging Quantity = 150