

CMS 322 Series 5MM Round Low Profile Fresnel Lens With Seal



5mm round fresnel lens with watertight seal

Notes

MOUNTING: Mounts in a $\text{Ø}.281 \pm .002$ [$\text{Ø } 7.13\text{mm} \pm .05$] panel hole on $.375$ [9.5mm] centers. Panel thickness $.031$ [$.8\text{mm}$] to $.125$ [3.18mm]. Panel hole should be deburred, but not chamfered.

ASSEMBLY: Insert lens through panel hole, slide RNG 268 retainer on back of lens. PCB mounted LEDs slide into lens when the panel cover is closed or the PCB card is inserted into the case.

MATERIAL:

Lens- Polycarbonate, UL 94-V2

GLO Series- Polycarbonate & Acrylic blend




Seal- TPE

RNG 268 Retainer sold separately

Meets NEMA 4 Standards (Equivalent to IP55 rating)

U.S. & Foreign Pat. Issued & Pend.

Product Dimensions

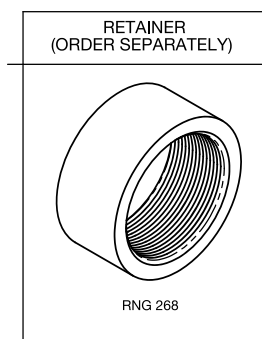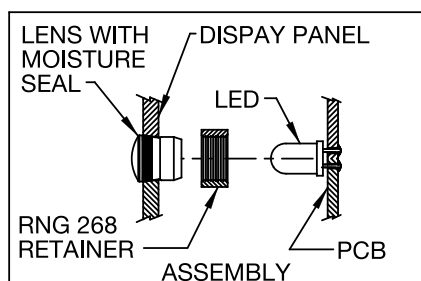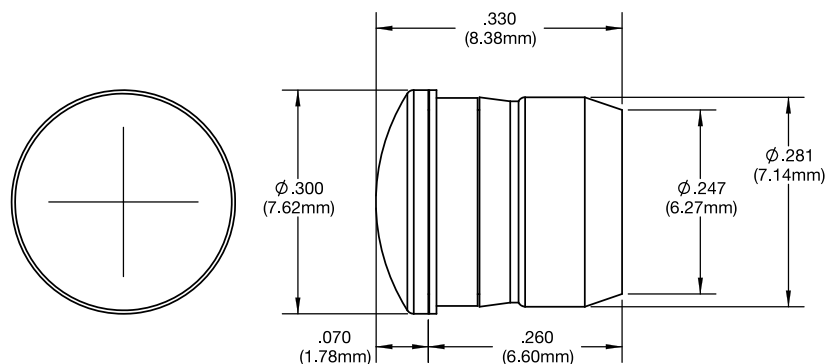

Ordering Data

ORDERING CODE : CMS 322 XXX

MODEL

LENS COLOR	
RTP	RED TRANSPARENT
ATP	AMBER TRANSPARENT
GTP	GREEN TRANSPARENT
BTP	BLUE TRANSPARENT
YTP	YELLOW TRANSPARENT
CTP	CLEAR TRANSPARENT
GLO	WHITE TRANSLUCENT

Compliances and Approvals

