


Item no.: 2001-1401
 Product description: 4-conductor through terminal block SUITABLE FOR EX E APPLICATIONS

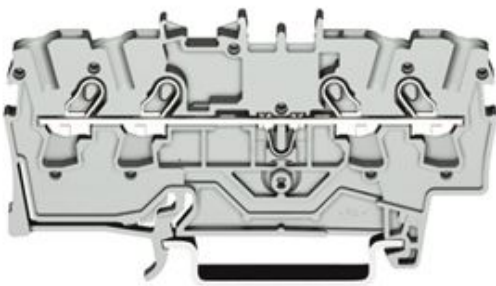

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

Current intensity EN	24 A
Product group	22 (TOPJOB S RAIL-MOUNTED TERMINAL BLOCKS)
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [AWG]	22 - 14 AWG
Connection method	CONTACT CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.25 - 2.5 mm ²
Cross section [AWG]	22 - 14 AWG
Wiring method	e+f
Connection method	CONTACT CAGE CLAMP® CONNECTION
Measured voltage EN	800 V
Measured shock voltage	8 kV
Pollution degree	3
Current intensity EN	18 A
Weight	5.137 g
Color	gray
Wiring type	Front-entry
No. of connection Points	4
No. of potentials	1
Height	33 mm
Height	1.299 in

Width
Width

4.2 mm
0.165 in



Depth	70 mm
Depth	2.76 in
Strip length from	9 mm
Strip length to	11 mm
Strip length	0.39 in
Country of Origin	Deutschland
Customs Tariff No.	85369010
Mounting	TS 35



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
2001-1401	ABS	05-HG476175/1-PDA	800	18	0,5-2,5
2001-1401	AEX	E185892	550	15	22-14
2001-1401	CCA	NL6386	800	18/24	0,5-1,5/2,5
2001-1401	CSA	154112-1645434	600	15	22-14
2001-1401	GL	26187-05HH	800	18	0,25-1,5
2001-1401	IECEX	IECEXPTB05.0034U	550	16	0,5-2,5
2001-1401	KEMA	2116586.01	800	18	0,5-2,5
2001-1401	LR	91/20112(E6)	800	18	0,25 -2,5
2001-1401	PRS	TE/1718/880590/08	800	18	0,5-2,5
2001-1401	PTB	PTB05Atex1094U	550	16	0,5-2,5
2001-1401	RosTest	8189158	550	16	0,5-2,5
2001-1401	UR	E45172	600	15	22-14

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected