


Item no.: 2091-1423  
 Product description: 3 POLE PIN SPACING 3.5 MM / 0.138 IN

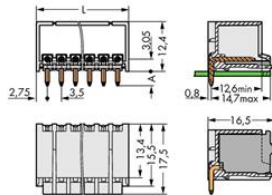

Produkt kann von Bild abweichen / product may differ

RoHS compliant

Color	light gray
pole count	3
Height	12.4 mm
Height	0.488 in
Width	12.5 mm
Width	0.492 in
Depth	17.5 mm
Depth	0.689 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Solder pin width, diam. [mm]	1 mm

Material group  
Customs Tariff No.

I  
85366990

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected