


Item no.: 218-102
 Product description: 1-CONDUCTOR PCB TERMINAL STRIP 2 POLE 2 SOLDER PINS / WITH LOCKING SIDE PIN SPACING 2.5 MM / 0.098 IN

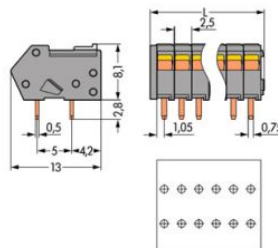

Produkt kann von Bild abweichen / product may differ

Packing unit 1000 10*100 pieces

| | |
|--------------------------|---------------------|
| Product group | 4 (Printed Circuit) |
| Weight | 0.728 g |
| Color | gray |
| No. of connection Points | 2 |
| No. of potentials | 2 |
| pole count | 2 |
| Height | 8.1 mm |
| Height | 0.319 in |
| Width | 6.5 mm |
| Width | 0.256 in |
| Depth | 13 mm |
| Depth | 0.512 in |
| Pin spacing from | 2.5 mm |
| Pin spacing from | 0.098 in |
| Pollution degree | 2 |
| Measured voltage EN | 160 V |
| Measured shock voltage | 2.5 kV |
| Current intensity EN | 6 A |
| Pollution degree | 2 |
| Measured voltage EN | 320 V |

Measured shock voltage
Current intensity EN

2.5 kV
6 A



| | |
|-------------------------------------|----------------------------|
| Connection method | CAGE CLAMP® CONNECTION |
| Cross section [mm ²] | 0.08 - 0.5 mm ² |
| Wiring method | solid |
| Cross section [mm ²] | 0.08 - 0.5 mm ² |
| Cross section to [mm ²] | 0.25 mm ² |
| Cross section to [mm ²] | 0.25 mm ² |
| Cross section [AWG] | 28 - 20 AWG |
| Strip length from | 5 mm |
| Strip length to | 6 mm |
| Material group | I |
| xxx-xxx/000-005 | red |
| xxx-xxx/000-006 | blue |
| xxx-xxx/000-012 | orange |
| xxx-xxx/000-023 | green |



| Item no. | Admission office | Approval no. | Voltage [V] | Current [A] | Cross section [mm ²] |
|----------|------------------|----------------|-------------|-------------|-----------------------------------|
| 218-102 | CCA | NL5749 | 250 | 6 | 0,8-0,5 |
| 218-102 | CSA | 154112-1565656 | 150 | 4 | 28-20 |
| 218-102 | KEMA | 2082146.01 | 250 | 6 | 0,8-0,5 |
| 218-102 | UR | E45172 | 150 | 4 | 28-20 |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected