


Item no.: 218-104  
 Product description: 1-CONDUCTOR PCB TERMINAL STRIP 4 POLE 2 SOLDER PINS / WITH LOCKING SIDE PIN SPACING 2.5 MM / 0.098 IN

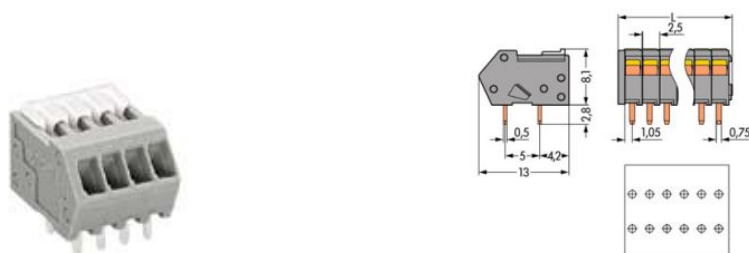

Produkt kann von Bild abweichen / product may differ

Packing unit 500 5\*100 pieces

RoHS compliant

Product group	4 (Printed Circuit)
Weight	1.364 g
Color	gray
No. of connection Points	4
No. of potentials	4
pole count	4
Height	8.1 mm
Height	0.319 in
Width	13 mm
Width	0.512 in
Depth	11.5 mm
Depth	0.453 in
Pin spacing from	2.5 mm
Pin spacing from	0.098 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	6 A
Pollution degree	2

Measured voltage EN	320 V
Measured shock voltage	2.5 kV
Current intensity EN	6 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm <sup>2</sup> ]	0.08 - 0.5 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.08 - 0.5 mm <sup>2</sup>
Cross section to [mm <sup>2</sup> ]	0.25 mm <sup>2</sup>
Cross section to [mm <sup>2</sup> ]	0.25 mm <sup>2</sup>
Cross section [AWG]	28 - 20 AWG
Strip length from	5 mm
Strip length to	6 mm
Material group	I
xxx-xxx/000-005	red
xxx-xxx/000-006	blue
xxx-xxx/000-012	orange
xxx-xxx/000-023	green



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
218-104	CCA	NL5749	250	6	0,08-0,5
218-104	CSA	154112-1565656	150	4	28-20
218-104	KEMA	2082146.01	250	6	0,08-0,5
218-104	UR	E45172	150	4	28-20

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected