


10

30

Lighting Connectors, Series 224
Description and Handling


Lighting (CAGE CLAMP®) side

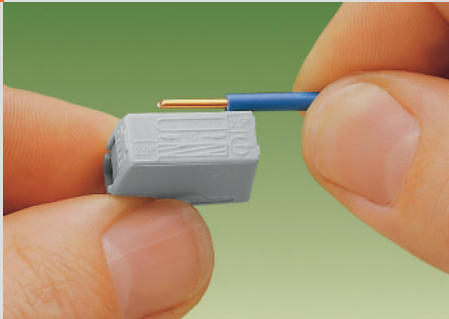

Strip conductor 9 – 11 mm /0.39 in



To connect: Press button fully and insert stripped conductor into square entry and release

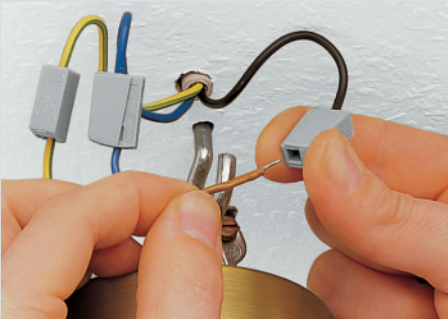

To remove: Press button and withdraw conductor

CAGE CLAMP® connects the following copper wires:*



solid



stranded



fine-stranded, also with tinned single strands




fine-stranded, tinned (up to 1.5 mm²/AWG 16)




fine-stranded, tip bonded




fine-stranded with ferrule (up to 1.5 mm²/AWG 16)

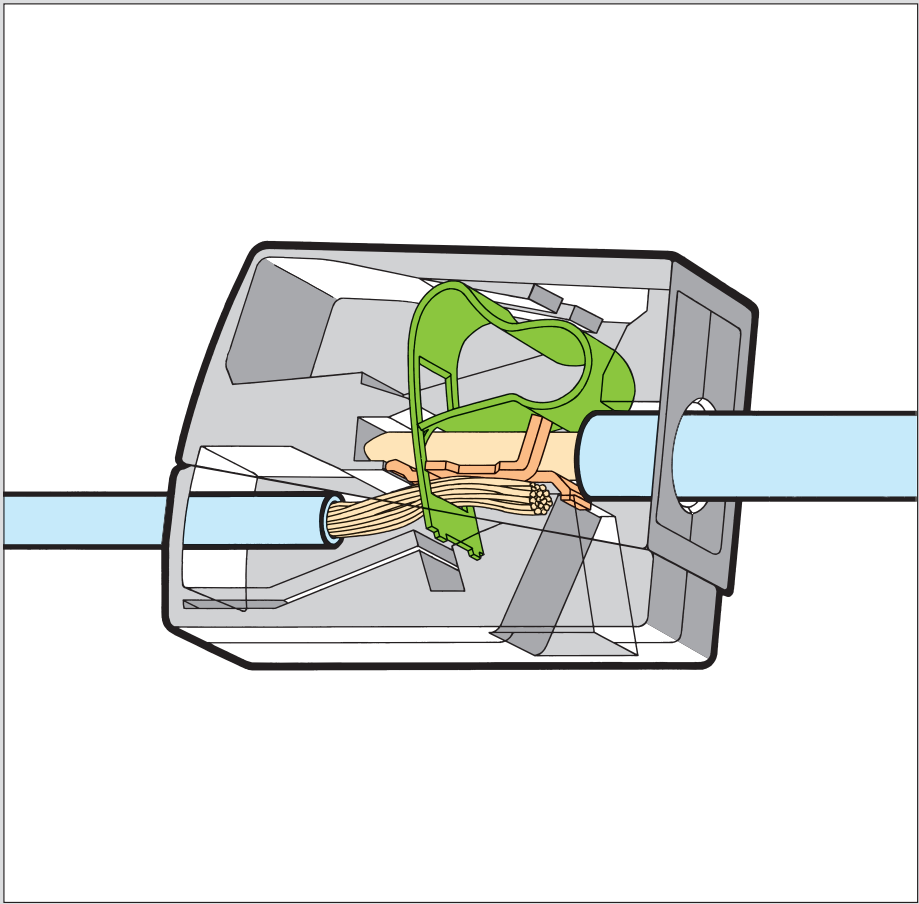

Installation/field (push-wire) side

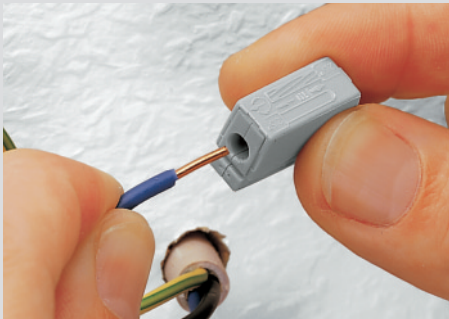

To connect: Introduce stripped solid conductor into circular entry and push to stop

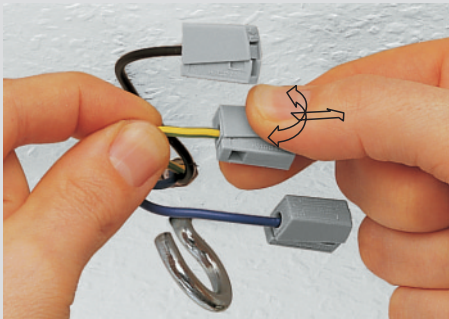

To remove: Hold conductor and twist connector alternately left and right while pulling the conductor



Testing through separate test slot

The push-wire connection connects the following copper wires:*



solid

* For aluminum wire see notes in section 15!