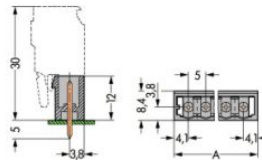

Item no.: 231-172/001-000
Product description: HEADER STRAIGHT SOLDER PIN, 1.2 X 1.2 MM /0.047 X 0.047 IN 12 POLE PIN SPACING 5 MM / 0.197 IN MATING DIRECTION PERPENDICULAR TO PCB WITH CLOSED END



Produkt kann von Bild abweichen / product may differ

Packing unit 100 4*25 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	4.806 g
Color	gray
pole count	12
Height	12 mm
Height	0.472 in
Width	63.2 mm
Width	2.488 in
Depth	8.4 mm
Depth	0.331 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V

Measured shock voltage	4 kV
Current intensity EN	12 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
231-172/001-000	ABS	04-HG469925/1-PDA	400	16	5,0
231-172/001-000	BV	11915/A0	400	16	2,5
231-172/001-000	CCA	5764	250	16	1,2x1,2
231-172/001-000	CSA	154112-1466354	300	15	
231-172/001-000	GL	17296-00HH	400	16	5,0
231-172/001-000	KEMA	2083746.02	250	16	1,2x1,2
231-172/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-172/001-000	LR	96/20035	400	16	5,0
231-172/001-000	RMR	11130002	400	16	5,0
231-172/001-000	UR	E45171	600	15	
231-172/001-000	UR	E45172	300	15	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected