


Item no.: 231-334/001-000
 Product description: HEADER STRAIGHT SOLDER PIN, 1X1 MM / 0.039X 0.039 IN
 4 POLE PIN SPACING 5.08 MM / 0.2 IN MATING DIRECTION
 PERPENDICULAR TO PCB WITH CLOSED END

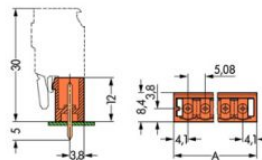

Produkt kann von Bild abweichen / product may differ

Packing unit 200 4*50 pieces

Product group	3 (Multi Conn. System)
Weight	1.433 g
Color	orange
pole count	4
Height	12 mm
Height	0.472 in
Width	23.52 mm
Width	0.926 in
Depth	8.4 mm
Depth	0.331 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV

Current intensity EN
Material group
Contact surface

12 A
I
tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
231-334/001-000	ABS	04-HG469925/1-PDA	400	12	0,8-2,5
231-334/001-000	BV	11915/A0	400	16	2,5
231-334/001-000	CCA	5764	250	12	1x1
231-334/001-000	CSA	154112-1466354	300	10	
231-334/001-000	GL	17296-00HH	400	12	0,8-2,5
231-334/001-000	KEMA	2083746.02	250	12	1x1
231-334/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-334/001-000	LR	96/20035	400	12	0,8-2,5
231-334/001-000	RMR	11130002	400	12	0,8-2,5
231-334/001-000	UR	E45171	600	15	
231-334/001-000	UR	E45172	300/150/300	10/10/10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected