


Item no.: 231-337/001-000  
 Product description: HEADER STRAIGHT SOLDER PIN, 1X1 MM / 0.039X 0.039 IN  
 7 POLE PIN SPACING 5.08 MM / 0.2 IN MATING DIRECTION  
 PERPENDICULAR TO PCB WITH CLOSED END

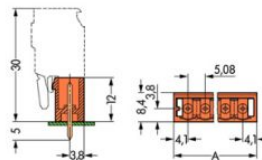

Produkt kann von Bild abweichen / product may differ

Packing unit 100 4\*25 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	2.4 g
Color	orange
pole count	7
Height	12 mm
Height	0.472 in
Width	38.76 mm
Width	1.526 in
Depth	8.4 mm
Depth	0.331 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V

Measured shock voltage	4 kV
Current intensity EN	12 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
231-337/001-000	BV	11915/A0	400	16	2,5
231-337/001-000	CCA	5764	250	12	1x1
231-337/001-000	CSA	154112-1466354	300	10	
231-337/001-000	KEMA	2083746.02	250	12	1x1
231-337/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-337/001-000	UR	E45171	600	15	
231-337/001-000	UR	E45172	300	10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected