




**Product Number:** 231-339/001-000

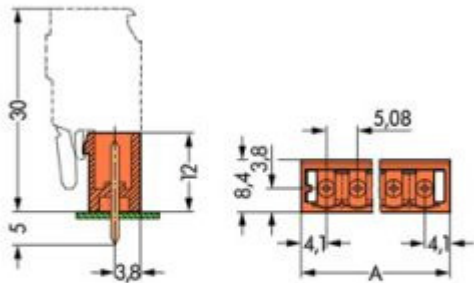

Diameter of drilled hole:  $1,4^{+0,1}$  mm

$A = (\text{No. of poles} \times \text{pin spacing}) + 3,2$  mm

**HEADER STRAIGHT SOLDER PIN, 1X1 MM / 0.039X 0.039 IN 9 POLE  
PIN SPACING 5.08 MM / 0.2 IN MATING DIRECTION PERPENDICULAR  
TO PCB WITH CLOSED END**

Packing unit 100 4\*25 pieces

**RoHS compliant**

Product group	3 (Multi Conn. System)
Weight	3.05 g
Color	Orange
pole count	9
Height	12 mm
Height	0.472 in
Width	48.92 mm
Width	1.926 in
Depth	8.4 mm

Depth	0.331 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Material group	I