


Item no.: 231-342/001-000  
 Product description: HEADER STRAIGHT SOLDER PIN, 1X1 MM / 0.039X 0.039 IN  
 12 POLE PIN SPACING 5.08 MM / 0.2 IN MATING  
 DIRECTION PERPENDICULAR TO PCB WITH CLOSED END

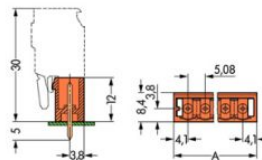

Produkt kann von Bild abweichen / product may differ

Packing unit 100 4\*25 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	4.018 g
Color	orange
pole count	12
Height	12 mm
Height	0.472 in
Width	64.16 mm
Width	2.526 in
Depth	8.4 mm
Depth	0.331 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V

Measured shock voltage	4 kV
Current intensity EN	12 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
231-342/001-000	ABS	04-HG469925/1-PDA	400	12	0,08-2,5
231-342/001-000	BV	11915/A0	400	16	2,5
231-342/001-000	CCA	5764	250	12	1x1
231-342/001-000	CSA	154112-1466354	300	10	
231-342/001-000	GL	17296-00HH	400	12	0,08-2,5
231-342/001-000	KEMA	2083746.02	250	12	1x1
231-342/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-342/001-000	LR	96/20035	400	12	0,08-2,5
231-342/001-000	RMR	11130002	400	12	0,08-2,5
231-342/001-000	UR	E45171	600	15	
231-342/001-000	UR	E45172	300	10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected