




**Product Number:** 231-346/001-000

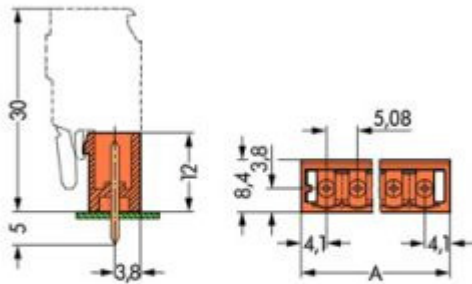

Diameter of drilled hole:  $1,4^{+0,1}$  mm

$A = (\text{No. of poles} \times \text{pin spacing}) + 3,2$  mm

**HEADER STRAIGHT SOLDER PIN, 1X1 MM / 0.039X 0.039 IN 16 POLE  
PIN SPACING 5.08 MM / 0.2 IN MATING DIRECTION PERPENDICULAR  
TO PCB WITH CLOSED END**

Packing unit 50 5\*10 pieces

**RoHS compliant**

Product group	3 (Multi Conn. System)
Weight	5.2 g
Color	Orange
pole count	16
Height	12 mm
Height	0.472 in
Width	84.48 mm
Width	3.326 in

Depth	8.4 mm
Depth	0.331 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Material group	I