


Item no.: 231-554/001-000
 Product description: HEADER RIGHT ANGLE SOLDER PIN, 1 X 1 MM / 0.039 X 0.039 IN 24 POLE PIN SPACING 5.08 MM / 0.2 IN MATING DIRECTION PARALLEL TO PCB WITH CLOSED END

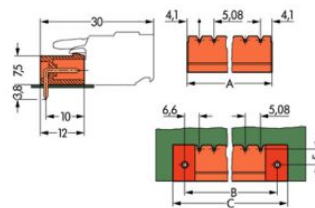

Produkt kann von Bild abweichen / product may differ

Packing unit 50 5*10 pieces

Product group	3 (Multi Conn. System)
Weight	7.85 g
Color	orange
pole count	24
Height	8.4 mm
Height	0.331 in
Width	125.12 mm
Width	4.926 in
Depth	12 mm
Depth	0.472 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV

Current intensity EN
Material group
Contact surface

16 A
I
tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
231-554/001-000	ABS	04-HG469925/1-PDA	400	12	0,8-2,5
231-554/001-000	BV	11915/A0	400	16	2,5
231-554/001-000	CCA	5764	250	12	1x1
231-554/001-000	CSA	154112-1466354	300	10	
231-554/001-000	GL	17296-00HH	400	12	0,8-2,5
231-554/001-000	KEMA	2083746.02	250	12	1x1
231-554/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-554/001-000	LR	96/20035	400	12	0,8-2,5
231-554/001-000	RMR	11130002	400	12	0,8-2,5
231-554/001-000	UR	E45172	300/150/300	10/10/10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected