


Item no.: 231-563/001-000  
 Product description: HEADER RIGHT ANGLE SOLDER PIN, 1.2 X 1.2 MM/ 0.47 X 0.47 IN 3 POLE PIN SPACING 5.08 MM / 0.2 IN MATING DIRECTION PARALLEL TO PCB WITH CLOSED END

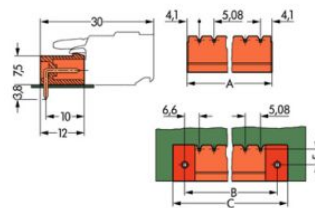

Produkt kann von Bild abweichen / product may differ

Packing unit 200 4\*50 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	1.2 g
Color	orange
pole count	3
Height	8.4 mm
Height	0.331 in
Width	18.44 mm
Width	0.726 in
Depth	12 mm
Depth	0.472 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V

Measured shock voltage	4 kV
Current intensity EN	16 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
231-563/001-000	ABS	04-HG469925/1-PDA	400	12	0,08-2,5
231-563/001-000	BV	11915/A0	400	16	2,5
231-563/001-000	CCA	5764	250	16	1,2x,21
231-563/001-000	CSA	154112-1466354	300	15	
231-563/001-000	GL	17296-00HH	400	12	0,08-2,5
231-563/001-000	KEMA	2083746.02	250	16	1,2x,21
231-563/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-563/001-000	LR	96/20035	400	12	0,08-2,5
231-563/001-000	RMR	11130002	400	12	0,08-2,5
231-563/001-000	UR	E45172	300	15	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected