
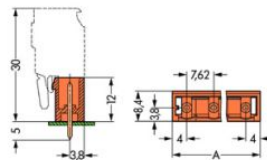


Item no.: 231-742/001-000  
 Product description: HEADER STRAIGHT SOLDER PIN, 1X1 MM / 0.039X 0.039 IN  
 12 POLE PIN SPACING 7.62 MM / 0.3 IN WITH CLOSED END  
 MATING DIRECTION PERPENDICULAR TO PCB

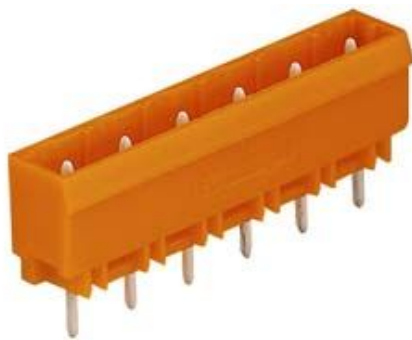

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

Product group	3 (Multi Conn. System)
Weight	4.79 g
Color	orange
pole count	12
Height	12 mm
Height	0.472 in
Width	91.82 mm
Width	3.615 in
Depth	8.4 mm
Depth	0.331 in
Pin spacing from	7.62 mm
Pin spacing from	0.3 in
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	6 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	6 kV

Current intensity EN  
Material group  
Contact surface

12 A  
I  
tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
231-742/001-000	ABS	04-HG469925/1-PDA	400	12	
231-742/001-000	BV	11915/A0	400	16	2,5
231-742/001-000	CCA	5764	400	12	1x1
231-742/001-000	CSA	154112-1466354	300	10	
231-742/001-000	GL	17296-00HH	400	12	
231-742/001-000	KEMA	2083746.02	400	12	1x1
231-742/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-742/001-000	LR	96/20035	400	12	
231-742/001-000	RMR	11130002	400	12	
231-742/001-000	UR	E45171	600	10	
231-742/001-000	UR	E45172	300/150/300	10/10/10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected