


Item no.: 231-968/001-000
 Product description: HEADER RIGHT ANGLE SOLDER PIN, 1.2 X 1.2 MM/ 0.47 X 0.47 IN 8 POLE PIN SPACING 7.62 MM / 0.3 IN WITH CLOSED END MATING DIRECTION PARALLEL TO PCB

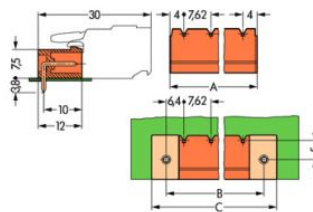

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	3.71 g
Color	orange
pole count	8
Height	8.4 mm
Height	0.331 in
Width	61.34 mm
Width	2.415 in
Depth	12 mm
Depth	0.472 in
Pin spacing from	7.62 mm
Pin spacing from	0.3 in
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	6 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	1000 V

Measured shock voltage	6 kV
Current intensity EN	16 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
231-968/001-000	ABS	04-HG469925/1-PDA	400	12	
231-968/001-000	BV	11915/A0	400	16	2,5
231-968/001-000	CCA	5764	400	16	1,2x1,2
231-968/001-000	CSA	154112-1466354	300	15	
231-968/001-000	GL	17296-00HH	400	12	
231-968/001-000	KEMA	2083746.02	400	16	1,2x1,2
231-968/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-968/001-000	LR	96/20035	400	12	
231-968/001-000	RMR	11130002	400	12	
231-968/001-000	UR	E45171	600	15	
231-968/001-000	UR	E45172	300	15	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected