


Item no.: 232-166
 Product description: FEMALE CONNECTOR WITH STRAIGHT SOLDER PIN 6
 POLE PIN SPACING 5.08 MM / 0.2 IN SOLDER PIN 0.6x1 MM
 WITH CODING FINGERS MATING DIRECTION
 PERPENDICULAR TO PCB WITH INTEGRATED FIXING
 FLANGES

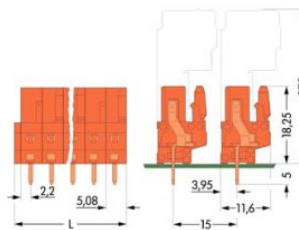

Packing unit 50 pieces

Product group	3 (Multi Conn. System)
Weight	5.45 g
Color	orange
No. of connection Points	6
No. of potentials	6
pole count	6
Height	18.25 mm
Height	0.719 in
Width	31.98 mm
Width	1.259 in
Depth	11.6 mm
Depth	0.457 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV

Current intensity EN

12 A

Material group

I

xxx-xxx/031-000

with fixing flange

xxx-xxx/039-000

with locking devices

xxx-xxx/047-000

with spacers



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
232-166	ABS	04-HG469925/1-PDA	250	12	0,8-2,5
232-166	BV	11915/A0	400	16	2,5
232-166	CCA	5764	250	12	0,6x1
232-166	CSA	154112-1466354	300	15	0,6x1
232-166	GL	17296-00HH	250	12	0,8-2,5
232-166	KEMA	2083746.02	250	12	0,6x1
232-166	KR	HMB05880-EL003	250/400	12/16	2,5
232-166	LR	96/20035	250	12	0,8-2,5
232-166	RMR	11130002	250	12	0,8-2,5
232-166	UR	E45172	300/150/300	15/15/10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected