


Item no.: 235-858/331-000
 Product description: 2-CONDUCTOR PCB TERMINAL STRIP 2 SOLDER PINS /
 POLE 8 POLE PIN SPACING 10/10.16 MM / 0.4 IN WITH
 PUSH BUTTONS

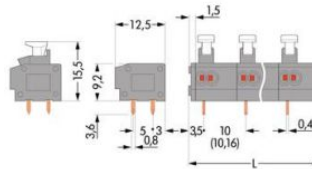

Produkt kann von Bild abweichen / product may differ

Packing unit 60 4*15 pieces

Weight	8.464 g
Color	gray
No. of connection Points	16
No. of potentials	16
pole count	8
Height	15.5 mm
Height	0.61 in
Width	81.5 mm
Width	3.209 in
Depth	12.5 mm
Depth	0.492 in
Pin spacing from	10 mm
Pin spacing up to	10.16 mm
Pin spacing from	0.394 in
Pin spacing up to	0.4 in
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	10 A

Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV



Current intensity EN	10 A
Connection method	PUSH WIRE®
Cross section [mm ²]	0.2 - 0.75 mm ²
Wiring method	solid
Cross section [AWG]	24 - 18 AWG
Strip length from	9 mm
Strip length to	10 mm
Material group	I



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
235-858/331-000	CCA	NL6309	500	10	0,25-0,75
235-858/331-000	CSA	154112-1673956	300	10	24-18
235-858/331-000	KEMA	2110204.16	500	10	0,25-0,75
235-858/331-000	UR	E45172	300	10	24-18

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected