


Item no.: 236-402/000-009/999-950
 Product description: Ex e II PCB terminal strip 2 SOLDER PINS / POLE 2 POLE
 SUITABLE FOR EX E APPLICATIONS PIN SPACING 5/5.08
 MM / 0.2 IN

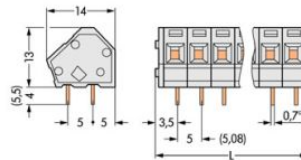

Produkt kann von Bild abweichen / product may differ

Packing unit 420 pieces

RoHS compliant

Weight	1.894 g
Color	light gray
No. of connection Points	2
No. of potentials	2
pole count	2
Height	13 mm
Height	0.512 in
Width	12.3 mm
Width	0.484 in
Depth	14 mm
Depth	0.551 in
Pin spacing from	5 mm
Pin spacing up to	5.08 mm
Pin spacing from	0.197 in
Pin spacing up to	0.2 in
Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	solid

Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	fine-stranded
Cross section [mm ²]	0.25 - 1.5 mm ²
Wiring method	fine-stranded (with ferrule and plastic collar)



Cross section [mm ²]	0.25 - 1.5 mm ²
Wiring method	fine-stranded (with ferrule, without plastic collar)
Cross section [AWG]	28 - 12 AWG
Strip length from	5 mm
Strip length to	6 mm
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated
xxx-xxx/332-009/999-950	with 5,5 mm long solder pins



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
236-402/000-009/999-950	AEX	E185892	300	15	28-12
236-402/000-009/999-950	GOSENERGO-Ex	99.041	175	16	0,5-2,5
236-402/000-009/999-950	PTB	IECExPTB06.0042U	176	16	0,5-2,5
236-402/000-009/999-950	PTB	PTB06ATEX1061U	176	16	0,5-2,5
236-402/000-009/999-950	RosTest	8189158	176	16	0,5-2,5

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected