


Item no.: 250-120/000-012  
 Product description: 1-CONDUCTOR PCB TERMINAL STRIP 1 FRONT SOLDER  
 PIN / POLE 20 POLE WITH PUSH BUTTONS PIN SPACING  
 3.5 MM / 0.138 IN WITH TEST SLOT FOR TEST PLUG TO 1.3  
 MM Ø

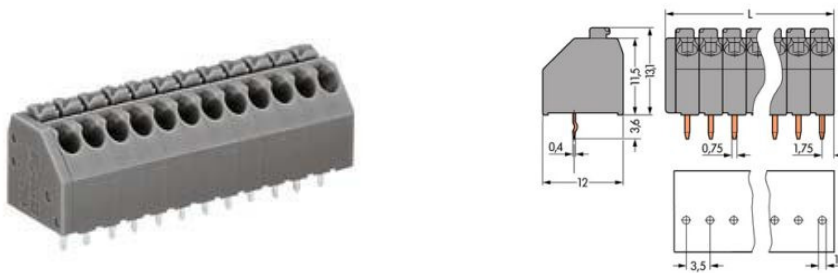

Produkt kann von Bild abweichen / product may differ

Packing unit 60 4\*15 pieces

RoHS compliant

Product group	4 (Printed Circuit)
Weight	9.171 g
Color	orange
No. of connection Points	20
No. of potentials	20
pole count	20
Height	13.1 mm
Height	0.516 in
Width	71.5 mm
Width	2.815 in
Depth	12 mm
Depth	0.472 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV

Current intensity EN	8 A
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	2.5 kV
Current intensity EN	8 A



Cross section [mm <sup>2</sup> ]	0.2 - 1.5 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.2 - 1.5 mm <sup>2</sup>
Wiring method	fine-stranded
Cross section [mm <sup>2</sup> ]	0.25 - 1 mm <sup>2</sup>
Wiring method	fine-stranded (with ferrule and plastic collar)
Cross section [mm <sup>2</sup> ]	0.25 - 1 mm <sup>2</sup>
Wiring method	fine-stranded (with ferrule, without plastic collar)
Cross section [AWG]	24 - 16 AWG
Strip length from	8.5 mm
Strip length to	9.5 mm
Material group	I
Contact surface	Copper



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
250-120/000-012	CSA	154112-1132097	300	10	20-16
250-120/000-012	UR	E45172	300	5	24-16

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected