


Item no.: 250-204
 Product description: 1-CONDUCTOR PCB TERMINAL STRIP 1 SOLDER PIN /
 POLE STAGGERED 4 POLE PIN SPACING 3.5 MM / 0.138 IN
 WITH PUSH BUTTONS WITH TEST SLOT FOR TEST PLUG
 TO 1.3 MM Ø

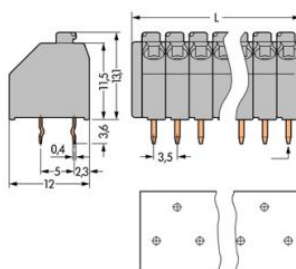

Produkt kann von Bild abweichen / product may differ

Packing unit 300 4*75 pieces

RoHS compliant

| | |
|--------------------------|---------------------|
| Product group | 4 (Printed Circuit) |
| Weight | 2.04 g |
| Color | gray |
| No. of connection Points | 4 |
| No. of potentials | 4 |
| pole count | 4 |
| Height | 13.1 mm |
| Height | 0.516 in |
| Width | 15.5 mm |
| Width | 0.61 in |
| Depth | 12 mm |
| Depth | 0.472 in |
| Pin spacing from | 3.5 mm |
| Pin spacing from | 0.138 in |
| Pollution degree | 2 |
| Measured voltage EN | 320 V |
| Measured shock voltage | 4 kV |

| | |
|------------------------|-------|
| Current intensity EN | 8 A |
| Pollution degree | 2 |
| Measured voltage EN | 630 V |
| Measured shock voltage | 4 kV |
| Current intensity EN | 8 A |



| | |
|----------------------------------|--|
| Cross section [mm ²] | 0.2 - 1.5 mm ² |
| Wiring method | solid |
| Cross section [mm ²] | 0.2 - 1.5 mm ² |
| Wiring method | fine-stranded |
| Cross section [mm ²] | 0.25 - 1 mm ² |
| Wiring method | fine-stranded (with ferrule and plastic collar) |
| Cross section [mm ²] | 0.25 - 1 mm ² |
| Wiring method | fine-stranded (with ferrule, without plastic collar) |
| Cross section [AWG] | 24 - 16 AWG |
| Strip length from | 8.5 mm |
| Strip length to | 9.5 mm |
| Material group | I |
| Contact surface | Copper |
| xxx-xxx/000-002 | yellow |
| xxx-xxx/000-004 | black |
| xxx-xxx/000-005 | red |
| xxx-xxx/000-006 | blue |
| xxx-xxx/000-009 | light gray |
| xxx-xxx/000-012 | orange |
| xxx-xxx/000-014 | brown |
| xxx-xxx/000-017 | light green |
| xxx-xxx/000-024 | violet |
| xxx-xxx/000-050 | white |



| Item no. | Admission office | Approval no. | Voltage [V] | Current [A] | Cross section [mm ²] |
|----------|------------------|-------------------|-------------|-------------|-----------------------------------|
| 250-204 | ABS | 04-HG469925/1-PDA | 400 | 2 | 0,5-1,5 |
| 250-204 | BV | 11915/A0 | 200 | 2 | 0,5-1,5 |
| 250-204 | CCA | NL6336 | 400 | 8 | 0,2-1,5 |
| 250-204 | CSA | 154112-1132097 | 300 | 10 | 20-16 |
| 250-204 | DNV | E-9215 | 400 | 2 | 0,5-1,5 |
| 250-204 | GL | 17296-00HH | 400 | 2 | 0,5-1,5 |
| 250-204 | KEMA | 2114919.01 | 400 | 8 | 0,2-1,5 |
| 250-204 | RMR | 11130002 | 400 | 2 | 0,5-1,5 |
| 250-204 | UR | E45171 | 600 | 2 | 20-16 |
| 250-204 | UR | E45172 | 300 | 5 | 24-16 |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected