


Item no.: 255-416  
 Product description: PCB TERMINAL STRIP 2 SOLDER PINS / POLE 16 POLE  
 PIN SPACING 5/5.08 MM / 0.2 IN WITH PUSH BUTTONS

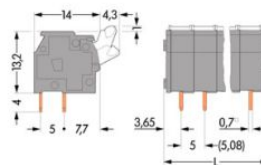

Produkt kann von Bild abweichen / product may differ

Packing unit 60 4\*15 pieces

Product group	4 (Printed Circuit)
Weight	18.47 g
Color	gray
No. of connection Points	16
No. of potentials	16
pole count	16
Height	14.2 mm
Height	0.559 in
Width	82.9 mm
Width	3.264 in
Depth	18.3 mm
Depth	0.72 in
Pin spacing from	5 mm
Pin spacing up to	5.08 mm
Pin spacing from	0.197 in
Pin spacing up to	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	24 A

Pollution degree  
Measured voltage EN

2  
630 V



Measured shock voltage	4 kV
Current intensity EN	24 A
Connection method	CAGE CLAMP® CONNECTION
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1.5 mm <sup>2</sup>
Cross section [AWG]	28 - 12 AWG
Strip length from	5 mm
Strip length to	6 mm
Material group	I
xxx-xxx/000-005	red
xxx-xxx/000-006	blue
xxx-xxx/000-008	dark gray
xxx-xxx/000-009	light gray
xxx-xxx/000-012	orange
xxx-xxx/000-017	light green



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
255-416	ABS	04-HG469925/1-PDA	500/250	16	0,5-2,5
255-416	BV	11915/A0	500/250	16	0,08-2,5
255-416	CCA	NL6248	250	24	0,08-2,5
255-416	CSA	18677-45	300/600	15/5	28-12
255-416	DNV	E-9215	500/250	16	0,08-2,5
255-416	GL	17296-00HH	500/250	16	0,5-2,5
255-416	KEMA	2110204.02	250	16	0,5-2,5
255-416	RMR	11130002	250	16	0,5-2,5
255-416	UR	E45172	300/300	15/10	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected