


Item no.: 257-402/333-000
 Product description: TERMINAL STROP WITH FINGER OPERATED LEVERS 2
 SOLDER PINS / POLE 2 POLE PIN SPACING 5/5.08 MM / 0.2
 IN

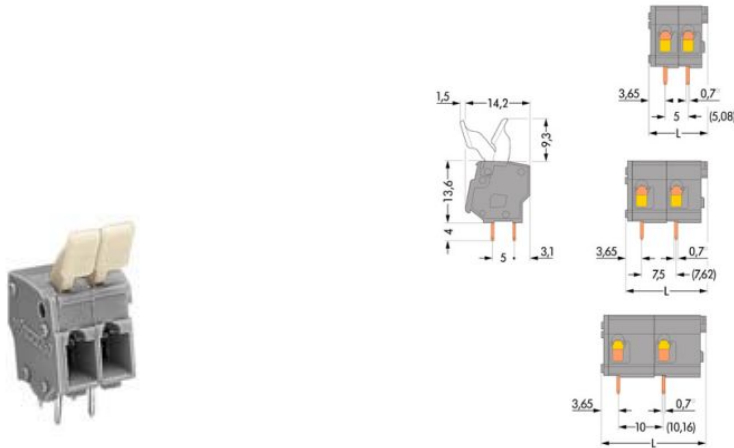

Produkt kann von Bild abweichen / product may differ

Packing unit 400 pieces

Product group	4 (Printed Circuit)
Weight	2.69 g
Color	gray
No. of connection Points	2
No. of potentials	2
pole count	2
Height	22.9 mm
Height	0.878 in
Width	5 mm
Width	0.197 in
Depth	15.7 mm
Depth	0.618 in
Pin spacing from	5 mm
Pin spacing up to	5.08 mm
Pin spacing from	0.197 in
Pin spacing up to	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV

Current intensity EN
Pollution degree
Measured voltage EN

24 A
2
630 V



Measured shock voltage	4 kV
Current intensity EN	24 A
Connection method	CAGE CLAMP® CONNECTION
Cross section [mm ²]	0.08 - 2.5 mm ²
Wiring method	solid
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [mm ²]	0.25 - 1.5 mm ²
Cross section [AWG]	28 - 24 AWG
Strip length from	5 mm
Strip length to	6 mm
Material group	I
xxx-xxx/000-005	red
xxx-xxx/333-006	blue
xxx-xxx/333-008	dark gray
xxx-xxx/333-009	light gray
xxx-xxx/333-012	orange
xxx-xxx/333-017	light green



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
257-402/333-000	ABS	04-HG469925/1-PDA	500/250	16	0,5-2,5
257-402/333-000	CCA	NL6250	250	24	0,08-2,5
257-402/333-000	GL	17296-00HH	500/250	16	0,5-2,5
257-402/333-000	KEMA	2110204.04	250	24	0,5-2,5
257-402/333-000	RMR	11130002	250	16	0,5-2,5

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected