



Color: ■ gray

Similar to illustration

Electrical data

Ratings per IEC/EN

Rated current	16 A
---------------	------

Physical data

Width	12 mm / 0.472 inches
Height	10 mm / 0.394 inches
Depth	5 mm / 0.197 inches
Jumper assignment	1-2

Material data

Note (material data)

[Information on material specifications can be found here](#)

Color	gray
Material group	I
Insulation material	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.01 MJ
Weight	0.9 g

Environmental requirements

Processing temperature	-35 ... +85 °C
Continuous operating temperature	-60 ... +105 °C

Commercial data	
Product Group	9 (Std Chassis Mt Blocks)
eCl@ss 10.0	27-14-11-40
eCl@ss 9.0	27-14-11-40
ETIM 8.0	EC000489
ETIM 7.0	EC000489
PU (SPU)	500 (25) pcs
Packaging type	Box
Country of origin	PL
GTIN	4045454342463
Customs tariff number	85366990990

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads

Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 262-402	↓

Documentation

Bid Text			
262-402	19.02.2019	xml 2.62 KB	↓
262-402	17.08.2017	doc 23.50 KB	↓

CAD/CAE-Data

CAD data	
2D/3D Models 262-402	↓

CAE data	
EPLAN Data Portal 262-402	↓
WSCAD Universe 262-402	↓
ZUKEN Portal 262-402	↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Tool

1.1.1.1 Operating tool




Item No.: 209-132

Operating tool; for connecting comb-style jumper bar; made of insulating material; 2-way; natural

Installation Notes

Commoning

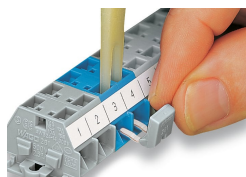

Commoning with comb-style jumper bar.