


Item no.: 264-104
 Product description: 2-CONDUCTOR TERMINAL STRIP WITH FIXING FLANGE FOR SCREW OR SIMILAR MOUNTING TYPES 3.2 MM Ø 4 POLE

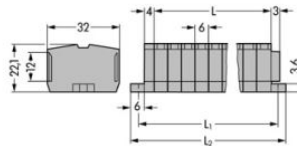

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

Product group	9 (Std Chassis Mt Blocks)
pole count	4
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [AWG]	28 - 12 AWG
Connection method	CAGE CLAMP® CONNECTION
Measured voltage EN	800 V
Measured shock voltage	8 kV
Pollution degree	3
Current intensity EN	24 A
Weight	17.4 g
Color	gray
Wiring type	Front-entry
No. of connection Points	8
No. of potentials	4
Height	22 mm
Height	0.867 in
Width	40 mm
Width	1.575 in

Depth	32 mm
Depth	1.26 in
Strip length from	8 mm
Strip length to	9 mm
Strip length	0.33 in
xxx-xxx/000-006	blue



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
264-104	ABS	04-HG476174/1-PDA	800	24	2,5
264-104	BV	07436/C0			0,08-2,5
264-104	CCA	NL6511	800	24	2,5
264-104	CSA	18677-23	600	20	26-12
264-104	DNV	E-9215	800	24	2,5
264-104	GL	17295-00HH	800	24	2,5
264-104	KEMA	2110272.04	800	24	2,5
264-104	KR	HMB05880-EL002	800	24	4
264-104	LR	92/20242(E5)	800	24	2,5
264-104	PRS	TE/1718/880590/08	800		2,5
264-104	RMR	11130002	800	24	2,5
264-104	UR	E45172	300	20	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected