


Item no.: 2706-102  
 Product description: 2 SOLDER PINS / POLE 2 POLE PIN SPACING 7.5 MM / 0.295 IN without jumper slot

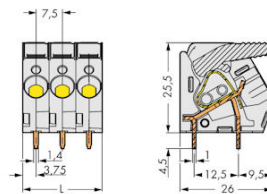

Produkt kann von Bild abweichen / product may differ

RoHS compliant

Color	gray
No. of connection Points	2
No. of potentials	2
pole count	2
Height	25.5 mm
Height	1.004 in
Width	15 mm
Width	0.591 in
Depth	26 mm
Depth	1.024 in
Pin spacing from	7.5 mm
Pin spacing from	0.295 in
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	6 kV
Current intensity EN	41 A
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	6 kV

Current intensity EN  
Connection method  
Cross section [mm<sup>2</sup>]

41 A  
CAGE CLAMP® CONNECTION  
0.5 - 6 mm<sup>2</sup>



Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.5 - 6 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.5 - 4 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.5 - 4 mm <sup>2</sup>
Cross section [AWG]	20 - 10 AWG
Strip length from	11 mm
Strip length to	12 mm
Material group	I

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected