


Item no.: 2706-304  
 Product description: 2 SOLDER PINS / POLE 4 POLE PIN SPACING 12.5 MM / 0.492 IN without jumper slot

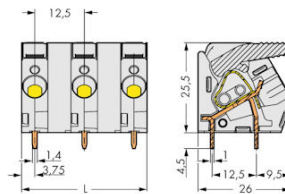

Produkt kann von Bild abweichen / product may differ

RoHS compliant

Color	gray
No. of connection Points	4
No. of potentials	4
pole count	4
Height	25.5 mm
Height	1.004 in
Width	45 mm
Width	1.772 in
Depth	26 mm
Depth	1.024 in
Pin spacing from	12.5 mm
Pin spacing from	0.492 in
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV
Current intensity EN	41 A
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	8 kV

Current intensity EN  
Connection method  
Cross section [mm<sup>2</sup>]

41 A  
CAGE CLAMP® CONNECTION  
0.5 - 6 mm<sup>2</sup>



Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.5 - 6 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.5 - 4 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.5 - 4 mm <sup>2</sup>
Cross section [AWG]	20 - 10 AWG
Strip length from	11 mm
Strip length to	12 mm
Material group	I

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected