


Item no.: 2706-307
 Product description: 2 SOLDER PINS / POLE 7 POLE PIN SPACING 12.5 MM / 0.492 IN without jumper slot

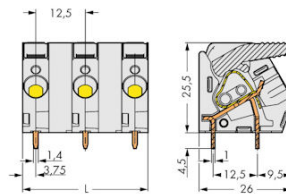

Produkt kann von Bild abweichen / product may differ

RoHS compliant

| | |
|--------------------------|----------|
| Color | gray |
| No. of connection Points | 7 |
| No. of potentials | 7 |
| pole count | 7 |
| Height | 25.5 mm |
| Height | 1.004 in |
| Width | 82.5 mm |
| Width | 3.248 in |
| Depth | 26 mm |
| Depth | 1.024 in |
| Pin spacing from | 12.5 mm |
| Pin spacing from | 0.492 in |
| Pollution degree | 2 |
| Measured voltage EN | 1000 V |
| Measured shock voltage | 8 kV |
| Current intensity EN | 41 A |
| Pollution degree | 2 |
| Measured voltage EN | 1000 V |
| Measured shock voltage | 8 kV |

Current intensity EN
Connection method
Cross section [mm²]

41 A
CAGE CLAMP® CONNECTION
0.5 - 6 mm²



| | |
|----------------------------------|-------------------------|
| Wiring method | solid |
| Cross section [mm ²] | 0.5 - 6 mm ² |
| Cross section [mm ²] | 0.5 - 4 mm ² |
| Cross section [mm ²] | 0.5 - 4 mm ² |
| Cross section [AWG] | 20 - 10 AWG |
| Strip length from | 11 mm |
| Strip length to | 12 mm |
| Material group | I |

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected